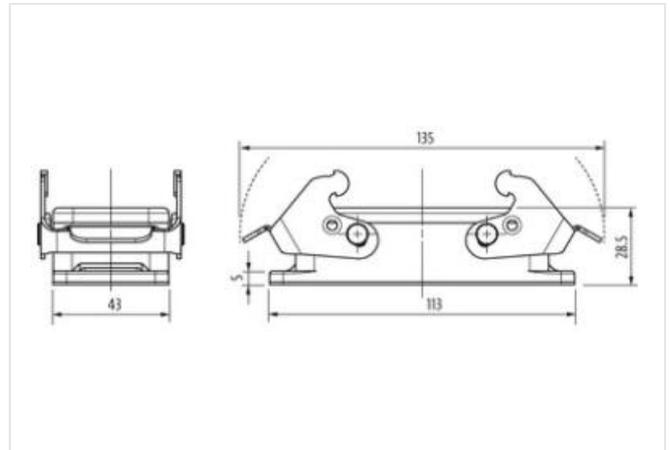


**B16 Bulkhead mounted h., IP65**

Double locking lever m.

B16  
Bulkhead mounted housing  
Double locking lever  
IP65

Technical data will be only guaranteed with Murrelektronik components.

**Link do produto****Ilustração**

Produto pode diferir da imagem

**Dados comerciais**

ECLASS-6.0	27143424
ECLASS-6.1	27261203
ECLASS-7.0	27440202
ECLASS-8.0	27440202
ECLASS-9.0	27440202
ECLASS-10.1	27440202
ECLASS-11.1	27440202
ECLASS-12.0	27440202
ETIM-5.0	EC000437
Classificação fiscal	85389099
GTIN	4048879646468
Quantidade por embalagem	1

**Installation | Connection**

Mating cycles min.	500
--------------------	-----

**Device protection | Electrical**

Degree of protection (EN IEC 60529)	IP65
Additional condition protection degree	inserted, locked, with screw connection

**Mechanical data**

Housing type	Bulkhead mounted housing
--------------	--------------------------

**Mechanical data | Material data**

Coating housing	powder-coated
Coating locking	verzinkt
Material gasket	NBR

Material housing	Aluminum die casting
------------------	----------------------

Locking material	Steel
------------------	-------

**Mechanical data | Mounting data**

Size	B16
------	-----

Height	28,5 mm
--------	---------

Width	43 mm
-------	-------

Depth	113 mm
-------	--------

Locking techniques	Double locking lever
--------------------	----------------------

**Environmental characteristics | Climatic**

Operating temperature min.	-40 °C
----------------------------	--------

Operating temperature max.	100 °C
----------------------------	--------

Climatic category (EN IEC 60068-1)	40/100/21
------------------------------------	-----------