


B24 Bulkhead mounted h., IP65

Double locking lever m.

B24
Bulkhead mounted housing
Double locking lever
IP65
Technical data will be only guaranteed with Murrelektronik components.

Link do produto

Ilustração

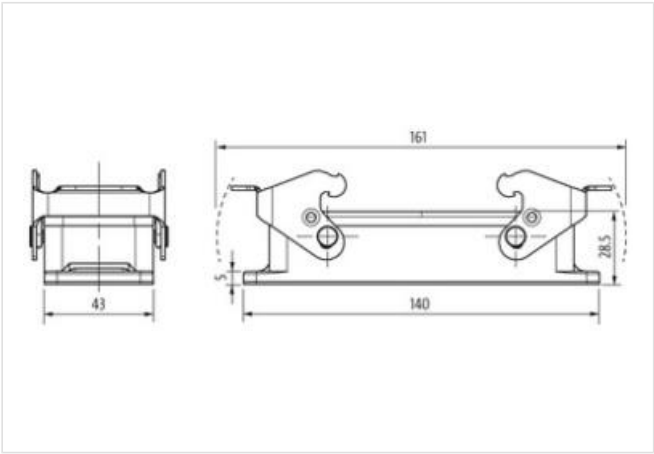

Produto pode diferir da imagem

Dados comerciais	
ECLASS-6.0	27143424
ECLASS-6.1	27261203
ECLASS-7.0	27440202
ECLASS-8.0	27440202
ECLASS-9.0	27440202
ECLASS-10.1	27440202
ECLASS-11.1	27440202
ECLASS-12.0	27440202
ETIM-5.0	EC000437
Classificação fiscal	85389099
GTIN	4048879646772
Quantidade por embalagem	1
Installation Connection	
Mating cycles min.	500
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP65
Additional condition protection degree	inserted, locked, with screw connection
Mechanical data	
Housing type	Bulkhead mounted housing
Mechanical data Material data	
Coating housing	powder-coated
Coating locking	verzinkt
Material gasket	NBR

Material housing	Aluminum die casting
------------------	----------------------

Locking material	Steel
------------------	-------

Mechanical data | Mounting data

Size	B24
------	-----

Height	28,5 mm
--------	---------

Width	43 mm
-------	-------

Depth	140 mm
-------	--------

Looking techniques	Double locking lever
--------------------	----------------------

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
----------------------------	--------

Operating temperature max.	100 °C
----------------------------	--------

Climatic category (EN IEC 60068-1)	40/100/21
------------------------------------	-----------