


B10 Coupling h., high profile, IP65

Double locking lever m., top entry M25

B10
Coupling housing (high)
Double locking lever
IP65
Technical data will be only guaranteed with Murrelektronik components.

[Link do produto](#)

Ilustração

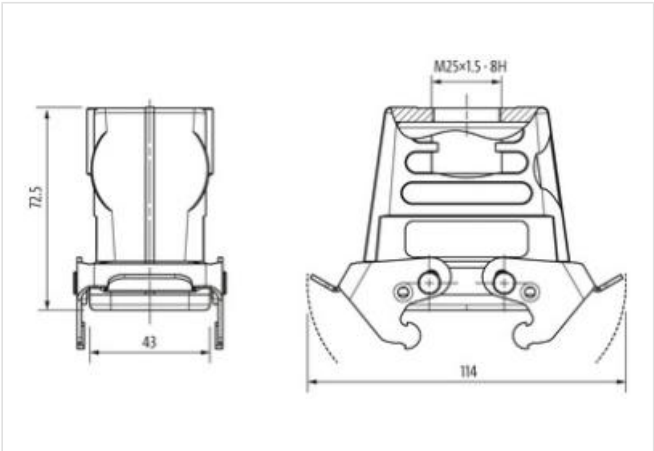

Produto pode diferir da imagem

Dados comerciais	
ECLASS-6.0	27143424
ECLASS-6.1	27261203
ECLASS-7.0	27440202
ECLASS-8.0	27440202
ECLASS-9.0	27440202
ECLASS-10.1	27440202
ECLASS-11.1	27440202
ECLASS-12.0	27440202
ETIM-5.0	EC000437
Classificação fiscal	85389099
GTIN	4048879644983
Quantidade por embalagem	1
Installation	
Cable outlet	straight
Installation Connection	
Mounting set	M25
Mating cycles min.	500
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP65
Additional condition protection degree	inserted, locked, with screw connection
Mechanical data	
Housing type	Coupling housing
Mechanical data Material data	

Coating housing	powder-coated
-----------------	---------------

Coating locking	verzinkt
-----------------	----------

Material gasket	NBR
-----------------	-----

Material housing	Aluminum die casting
------------------	----------------------

Locking material	Steel
------------------	-------

Mechanical data | Mounting data

Size	B10
------	-----

Height	72,5 mm
--------	---------

Width	43 mm
-------	-------

Depth	114 mm
-------	--------

Looking techniques	Double locking lever
--------------------	----------------------

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
----------------------------	--------

Operating temperature max.	100 °C
----------------------------	--------

Climatic category (EN IEC 60068-1)	40/100/21
------------------------------------	-----------