


B16 Surface mounted h., high profile, IP65

Single locking lever m.,2 entries M32, p-cover

B16
Surface mounted housing (high)
Single locking lever
IP65
Technical data will be only guaranteed with Murrelektronik components.

Link do produto

Ilustração

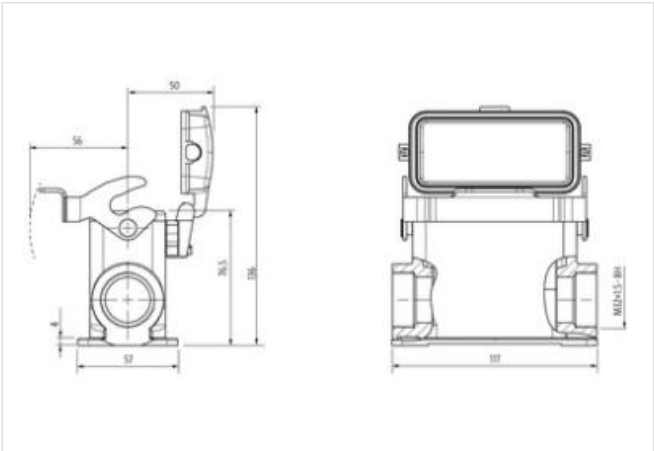

Produto pode diferir da imagem

Dados comerciais	
ECLASS-6.0	27143424
ECLASS-6.1	27261203
ECLASS-7.0	27440202
ECLASS-8.0	27440202
ECLASS-9.0	27440202
ECLASS-10.1	27440202
ECLASS-11.1	27440202
ECLASS-12.0	27440202
ETIM-5.0	EC000437
Classificação fiscal	85389099
GTIN	4048879646574
Quantidade por embalagem	1
Installation	
Cable outlet	double-sided
Installation Connection	
Mounting set	M32
Mating cycles min.	500
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP65
Additional condition protection degree	inserted, locked, with screw connection
Mechanical data	
Housing type	Surface mounted housing
Mechanical data Material data	

Coating housing	powder-coated
Coating locking	verzinkt
Material gasket	NBR
Material housing	Aluminum die casting
Material protective cover	Plastic
Locking material	Steel

Mechanical data | Mounting data

Size	B16
Height	76,5 mm
Width	57 mm
Depth	117 mm
Locking techniques	Single locking lever

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
Operating temperature max.	100 °C
Climatic category (EN IEC 60068-1)	40/100/21