


B16 Surface mounted h., low profile, IP65

Double locking lever m., side entry M25

B16
Surface mounted housing (low)
Double locking lever
IP65
Technical data will be only guaranteed with Murrelektronik components.

[Link do produto](#)

Ilustração

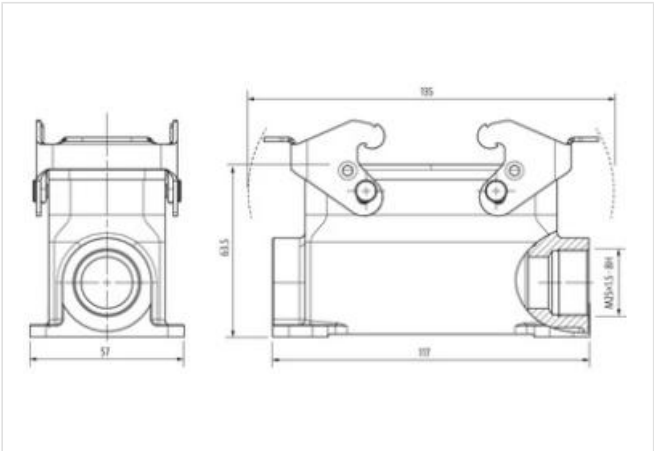

Produto pode diferir da imagem

Dados comerciais

ECLASS-6.0	27143424
ECLASS-6.1	27261203
ECLASS-7.0	27440202
ECLASS-8.0	27440202
ECLASS-9.0	27440202
ECLASS-10.1	27440202
ECLASS-11.1	27440202
ECLASS-12.0	27440202
ETIM-5.0	EC000437
Classificação fiscal	85389099
GTIN	4048879646512
Quantidade por embalagem	1

Installation

Cable outlet laterally

Installation | Connection

Mounting set	M25
Mating cycles min.	500

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65
Additional condition protection degree	inserted, locked, with screw connection

Mechanical data

Housing type Surface mounted housing

Mechanical data | Material data

Coating housing	powder-coated
Coating locking	verzinkt
Material gasket	NBR
Material housing	Aluminum die casting
Locking material	Steel

Mechanical data | Mounting data

Size	B16
Height	63,5 mm
Width	57 mm
Depth	117 mm
Looking techniques	Double locking lever

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
Operating temperature max.	100 °C
Climatic category (EN IEC 60068-1)	40/100/21