


B10 Hood, low profile, IP65

Double locking lever, top entry M20

B10
Hood (low)
Double locking lever
IP65
Technical data will be only guaranteed with Murrelektronik components.

Link do produto

Ilustração

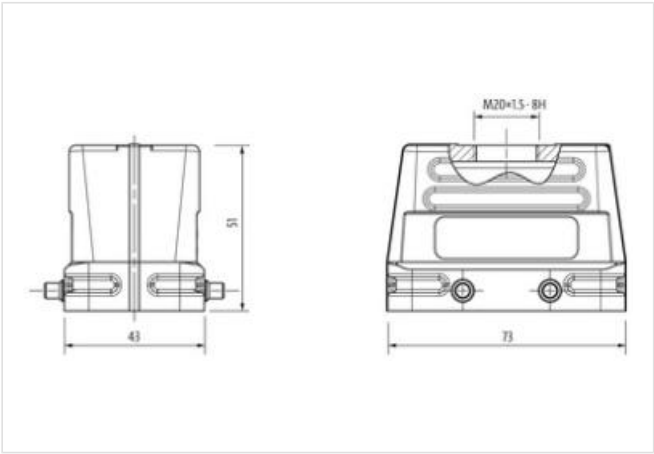

Produto pode diferir da imagem

Dados comerciais	
ECLASS-6.0	27143424
ECLASS-6.1	27261203
ECLASS-7.0	27440202
ECLASS-8.0	27440202
ECLASS-9.0	27440202
ECLASS-10.1	27440202
ECLASS-11.1	27440202
ECLASS-12.0	27440202
ETIM-5.0	EC000437
Classificação fiscal	85389099
GTIN	4048879646284
Quantidade por embalagem	1
Installation	
Cable outlet	straight
Installation Connection	
Mounting set	M20
Mating cycles min.	500
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP65
Additional condition protection degree	inserted, locked, with screw connection
Mechanical data	
Housing type	Hood
Mechanical data Material data	

Coating housing	powder-coated
-----------------	---------------

Coating locking	verzinkt
-----------------	----------

Material housing	Aluminum die casting
------------------	----------------------

Locking material	Steel
------------------	-------

Mechanical data | Mounting data

Size	B10
------	-----

Height	51 mm
--------	-------

Width	43 mm
-------	-------

Depth	73 mm
-------	-------

Locking techniques	Double locking lever
--------------------	----------------------

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
----------------------------	--------

Operating temperature max.	100 °C
----------------------------	--------

Climatic category (EN IEC 60068-1)	40/100/21
------------------------------------	-----------