


B16 Hood, IP68

Screw locking, top entry M40

B16
Hood
Screw locking
IP68
Technical data will be only guaranteed with Murrelektronik components.

Link do produto

Ilustração

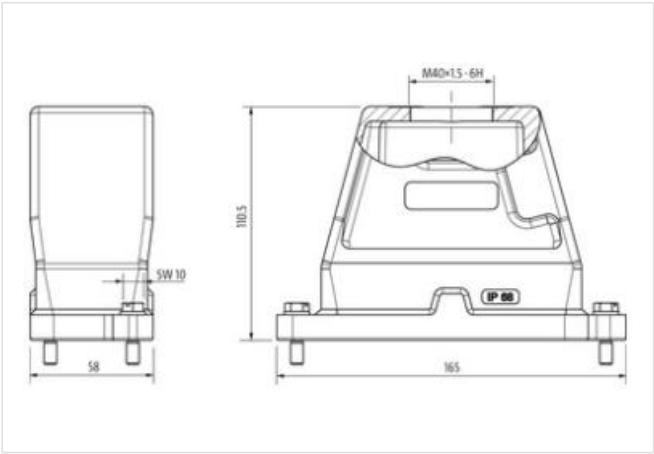

Produto pode diferir da imagem

Dados comerciais	
ECLASS-6.0	27143424
ECLASS-6.1	27261203
ECLASS-7.0	27440202
ECLASS-8.0	27440202
ECLASS-9.0	27440202
ECLASS-10.1	27440202
ECLASS-11.1	27440202
ECLASS-12.0	27440202
ETIM-5.0	EC000437
Classificação fiscal	85389099
GTIN	4048879647427
Quantidade por embalagem	1
Installation	
Cable outlet	straight
Installation Connection	
Tightening torque	4 Nm
Mounting set	M40
Mating cycles min.	500
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP68
Additional condition protection degree	inserted, locked, with screw connection
Mechanical data	
Housing type	Hood

Mechanical data Material data	
Coating housing	powder-coated
Material gasket	Silicon
Material housing	Aluminum die casting
Locking material	Stainless steel
Mechanical data Mounting data	
Size	B16
Mounting method	Screw locking
Height	110,5 mm
Width	58 mm
Depth	165 mm
Environmental characteristics Climatic	
Operating temperature min.	-40 °C
Operating temperature max.	125 °C
Climatic category (EN IEC 60068-1)	40/125/21