


RJ45 module - male, field wireable

Male
RJ45
field-wireable
Technical data will be only guaranteed with Murrelektronik components.
Crimping tool (Hirose) is required. Type: FB-TM21 / Art.-No. : HT601/TM21P-88P
The clip 70MH-ZZ100-0000000 is needed (2×)

Link do produto

Ilustração

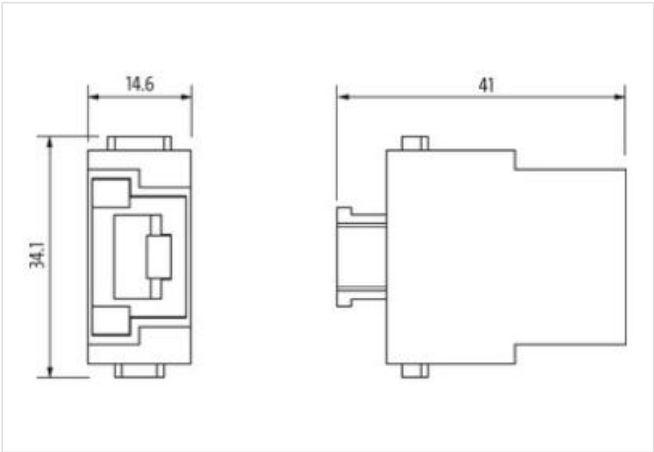

Produto pode diferir da imagem



Dados comerciais	
ECLASS-6.0	27143424
ECLASS-7.0	27440209
ECLASS-8.0	27440209
ECLASS-9.0	27440209
ECLASS-10.1	27440204
ECLASS-11.1	27440204
ECLASS-12.0	27440204
ETIM-5.0	EC000437
Classificação fiscal	85366990
GTIN	4048879664073
Quantidade por embalagem	1
Electrical data Supply	
Operating voltage AC	50 V
Operating voltage DC	50 V
Industrial communication	
Transfer parameters	CAT6A (IEC 60512-27-100:2008, TIA-568-C.2:2009)
Installation	
AWG number min.	27
AWG number max.	24

Installation Connection	
Gender	male
Mating cycles min.	500
Device protection Electrical	
Pollution Degree	3
Rated surge voltage	0,8 kV
Overvoltage category (EN 60950-1)	III
Mechanical data Material data	
Coating contact	gold plated
Combustibility class (UL94)	V-0
Material housing	PC
Material contact	Phosphor bronze
Mechanical data Mounting data	
Number of module slots	1
Height	41 mm
Width	34,1 mm
Depth	14,6 mm
Environmental characteristics Climatic	
Operating temperature min.	-25 °C
Operating temperature max.	60 °C