



Mini (7/8) 5 pole Tee, Male (Ext.)/2x Female

Yellow Housing


5-pole
T-coupler 7/8" – 7/8", female/male
Parallel circuit

Link do produto

Ilustração

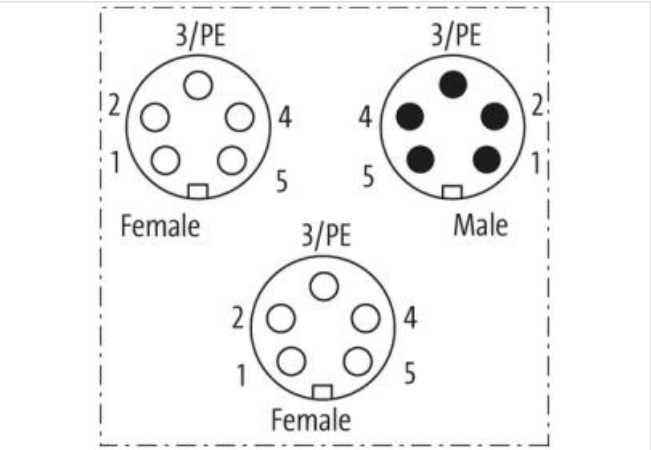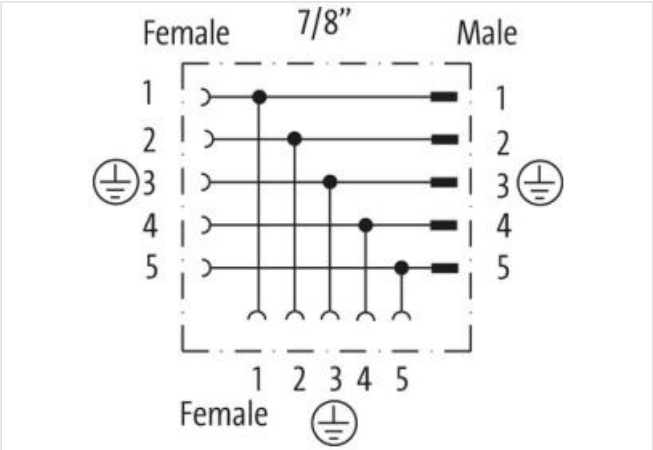

Produto pode diferir da imagem

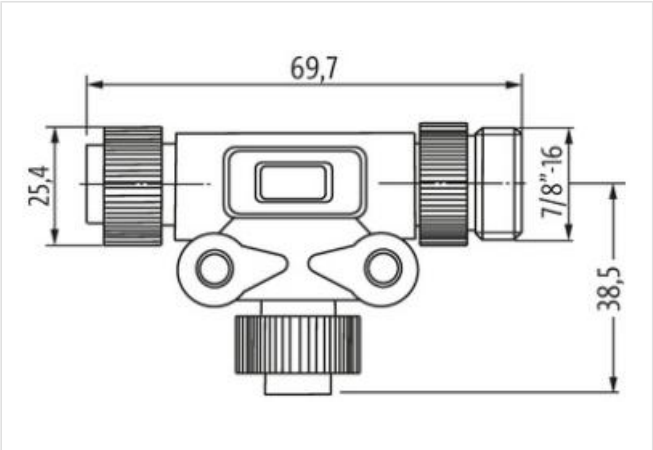

Dados comerciais	
ECLASS-10.1	27440106
ECLASS-11.1	27440106
ECLASS-12.0	27440106
Classificação fiscal	85366990
GTIN	4065909016145
Quantidade por embalagem	1
Electrical data Supply	

Operating voltage AC max.	600 V
---------------------------	-------

Operating voltage DC max.	600 V
---------------------------	-------

Current operating per contact max.	8 A
------------------------------------	-----

Installation | Connection

Mounting set	7/8"
--------------	------

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP67
-------------------------------------	------

Additional condition protection degree	inserted, screwed
--	-------------------

Pollution Degree	3
------------------	---

Mechanical data

Contour for corrugated hose	without
-----------------------------	---------

Mechanical data | Material data

Coating locking	eloxiert
-----------------	----------

Material housing	PVC
------------------	-----

Locking material	Aluminium
------------------	-----------

Mechanical data | Mounting data

Mounting method	Schraubgewinde
-----------------	----------------

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
----------------------------	--------

Operating temperature max.	105 °C
----------------------------	--------

Important installation notes

Note on strain relief	Protect the connectors by suitable measures from mechanical loads, e.g. by the usage of cable ties.
-----------------------	---

Note on bending radius	Attention: Observe the permissible bending radii when laying cables, as the IP protection class can be endangered by excessive bending forces.
------------------------	---