



MVP-METALL, 8XM12, 5POLE, M23 19POL. CON.

Connector exit frontside


8-way, 5-pole
M23 plug connection, 19-pole
Without LED for analog signals up to 48 V AC/DC
Replaces identical product (Art.No. 27536)
M12 contacts 1, 2, 3, 4 single wired; common PE

Link do produto

Ilustração

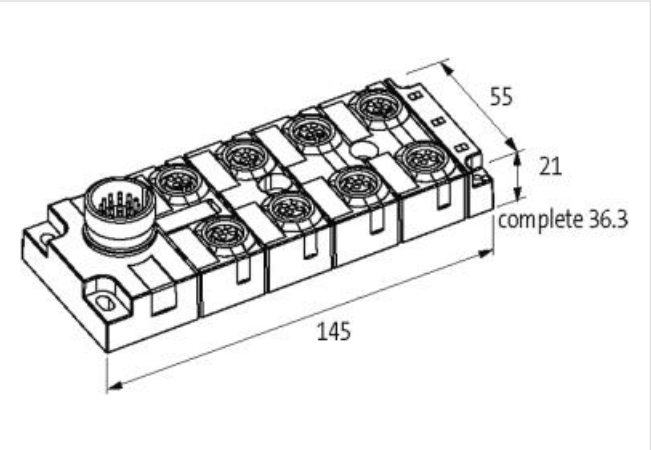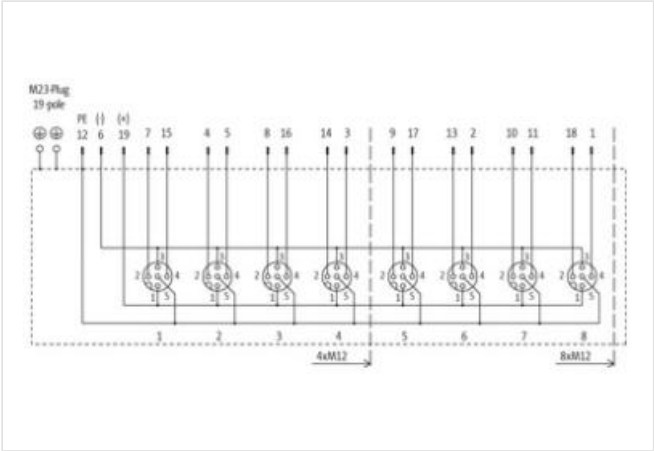

Produto pode diferir da imagem

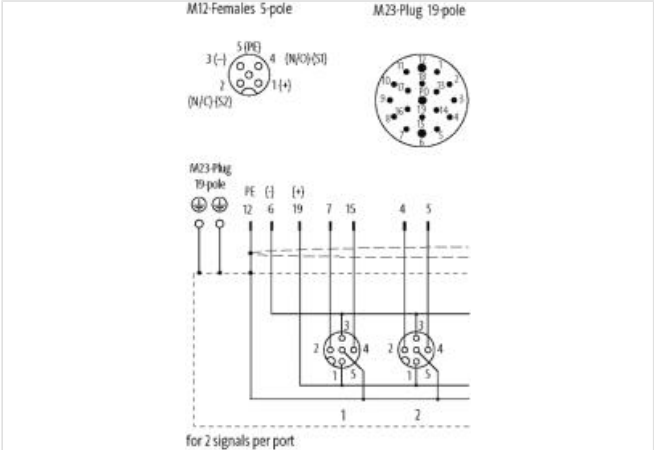

Dados comerciais	
ECLASS-6.0	27279219
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219

ECLASS-9.0	27440108
ECLASS-10.1	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ETIM-5.0	EC002585
Classificação fiscal	85369010
GTIN	4048879352895
Quantidade por embalagem	1

Electrical data | Supply

Operating voltage AC max.	48 V
Operating voltage DC max.	48 V
Current operating per contact max.	4 A
Total current max.	7,5 A

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65, IP67, IP68
-------------------------------------	------------------

Mechanical data | Material data

Coating housing	Nickel
Material housing	Zinc die-casting

Environmental characteristics | Climatic

Operating temperature min.	-25 °C
Operating temperature max.	80 °C

Connection type 2

Family construction form	M12
Gender	female
Color contact carrier	black
Coding	A
No. of poles	5
PIN 1	+
PIN 2	NC S 2
PIN 3	-
PIN 4	NO S 1
PIN 5	PE
Family construction form	M23
Gender	male
Color contact carrier	black
Coding	A
No. of poles	19
PIN 1	VT
PIN 2	RD
PIN 3	GY
PIN 4	RD / BU
PIN 5	GN
PIN 6	BU
PIN 7	GY / PK
PIN 8	WH / GN
PIN 9	WH / YE
PIN 10	WH / GY
PIN 11	BK
PIN 12	YE / GN
PIN 13	YE / BN
PIN 14	BN / GN
PIN 15	WH

PIN 16	YE
PIN 17	PK
PIN 18	GY / BN
PIN 19	BN