



CAP WITH SPRING PLUG TERMINALS 21 POLE

Use with MVP12 / Exact12 UNIVERSAL

4-way distribution box M12, UNIVERSAL
Spring clamp plug-in terminals
Replaces identical product (Art.No. 277314)
Plastic housings with good resistance against chemicals and oils.
The resistance to aggressive media should be individually tested for your application. Further details on request.

Link do produto

Ilustração

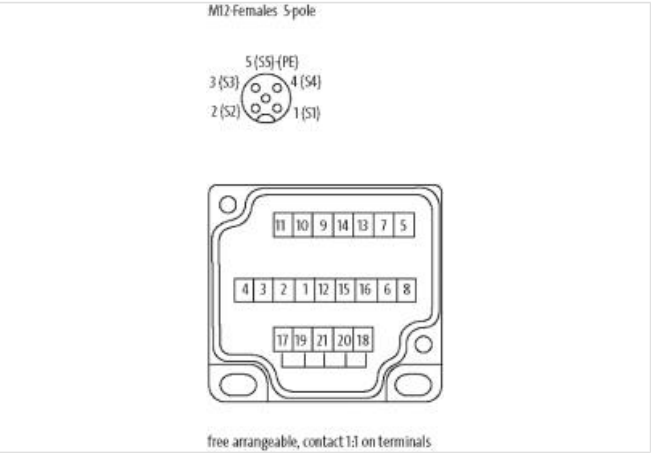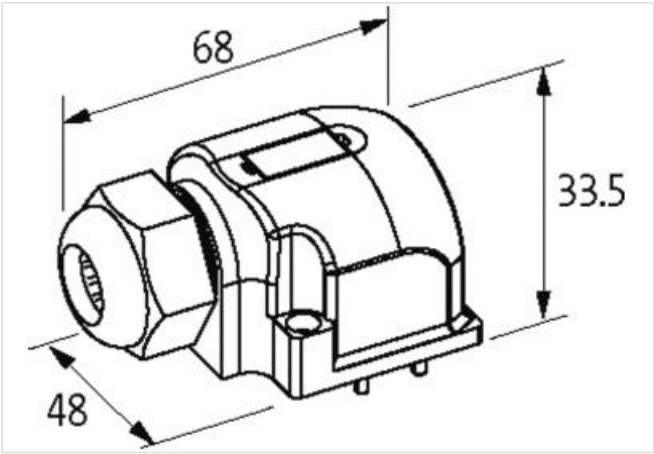

Produto pode diferir da imagem



Dados comerciais	
ECLASS-6.0	27143423
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440108

ECLASS-10.1	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ETIM-5.0	EC002585
Classificação fiscal	85366990
GTIN	4048879378529
Quantidade por embalagem	1
Electrical data Supply	
Total current max.	8 A
Installation	
Connection cross section max.	1,5 mm ²
AWG number max.	16
Installation Connection	
Connection	Spring clamp terminals FK
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Material housing	Plastic
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	80 °C
Connection type 2	
Family construction form	Cap
No. of poles	21
Family construction form	M12
Gender	female
Color contact carrier	black
Coding	A
No. of poles	5