



CAP. WITH SCREW PLUG TERMINALS 21 POLE

Use with MVP12 / Exact12 UNIVERSAL

Cap for 4-way distribution box, UNIVERSAL, 5-pole  
Plastic housings with good resistance against chemicals and oils.  
The resistance to aggressive media should be individually tested for your application. Further details on request.

Link do produto

Ilustração

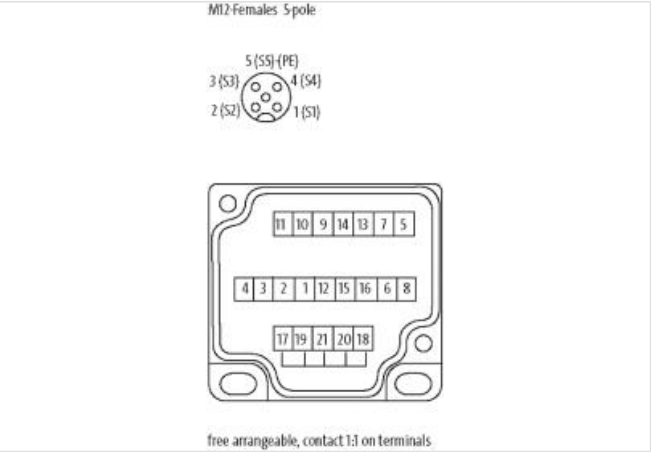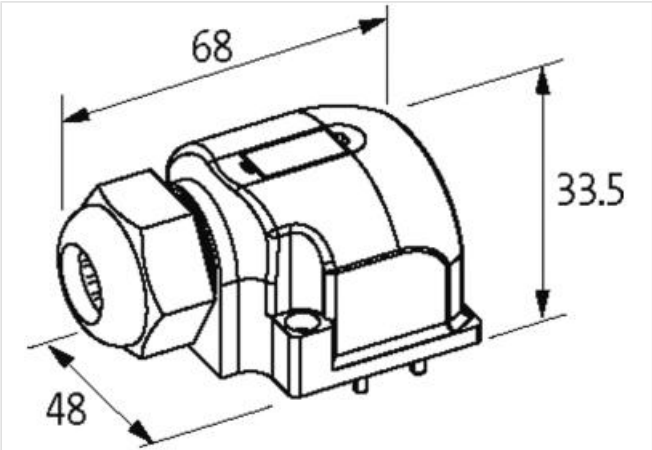

Produto pode diferir da imagem



| Dados comerciais |          |
|------------------|----------|
| ECLASS-6.0       | 27143423 |
| ECLASS-6.1       | 27279219 |
| ECLASS-7.0       | 27279219 |
| ECLASS-8.0       | 27279219 |
| ECLASS-9.0       | 27440108 |
| ECLASS-10.1      | 27440111 |

|                                                 |                         |
|-------------------------------------------------|-------------------------|
| ECLASS-11.1                                     | 27440111                |
| ECLASS-12.0                                     | 27440111                |
| ETIM-5.0                                        | EC002585                |
| Classificação fiscal                            | 85366990                |
| GTIN                                            | 4048879378536           |
| Quantidade por embalagem                        | 1                       |
| <b>Electrical data   Supply</b>                 |                         |
| Total current max.                              | 8 A                     |
| <b>Installation</b>                             |                         |
| Connection cross section max.                   | 1,5 mm <sup>2</sup>     |
| AWG number max.                                 | 16                      |
| <b>Installation   Connection</b>                |                         |
| Connection                                      | Screw plug-in terminals |
| <b>Device protection   Media</b>                |                         |
| Flame resistance                                | flame retardant         |
| <b>Mechanical data   Material data</b>          |                         |
| Material housing                                | Plastic                 |
| <b>Environmental characteristics   Climatic</b> |                         |
| Operating temperature min.                      | -20 °C                  |
| Operating temperature max.                      | 80 °C                   |
| <b>Connection type 2</b>                        |                         |
| Family construction form                        | Cap                     |
| No. of poles                                    | 21                      |
| Family construction form                        | M12                     |
| Gender                                          | female                  |
| Color contact carrier                           | black                   |
| Coding                                          | A                       |
| No. of poles                                    | 5                       |