



SAFETY WIRING SYSTEM

Distributor Box


8-way distribution box
with electrical feedback
with LED
Replaces identical product (Art.No. 27292)
Plastic housings with good resistance against chemicals and oils.
The resistance to aggressive media should be individually tested for your application. Further details on request.

Link do produto

Ilustração

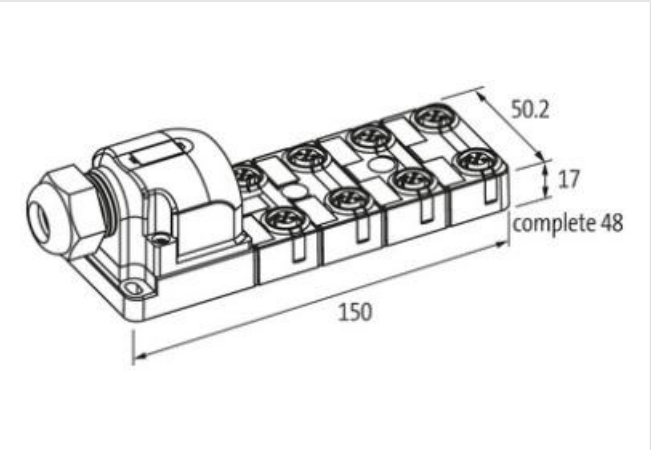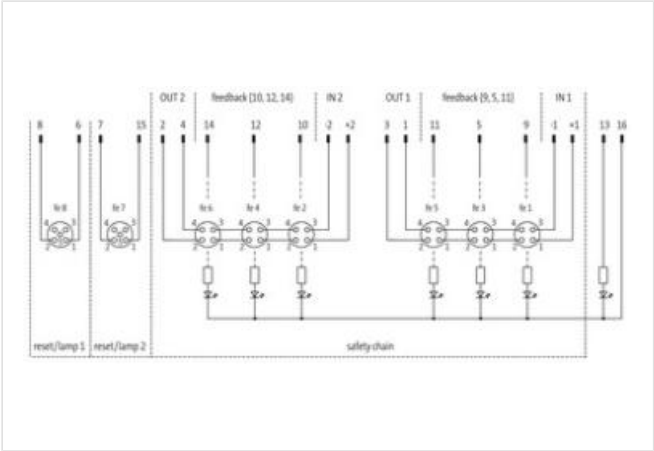

Produto pode diferir da imagem

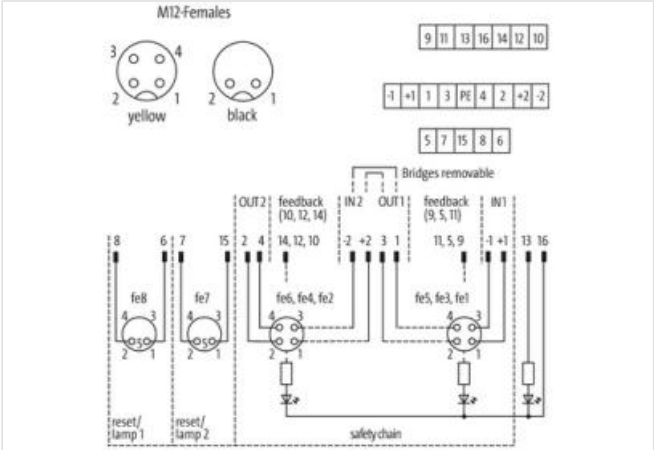

Dados comerciais	
ECLASS-6.0	27143423
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219

ECLASS-9.0	27440108
ECLASS-10.1	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ETIM-5.0	EC002585
Classificação fiscal	85369010
GTIN	4048879353373
Quantidade por embalagem	1

Electrical data | Supply

Operating voltage DC	24 V
Operating current per chain max.	1 A
Current operating per port max.	1 A

Installation | Connection

Mounting set	M12 x 1
--------------	---------

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP54
Insulation resistance min.	1000 MΩ
Overvoltage category (EN 60664-1)	III

Mechanical data | Mounting data

Mounting method	Schraubgewinde
-----------------	----------------

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	80 °C

Conformity

Product standard	EN 61131-2
------------------	------------

Connection type 3

Family construction form	Cap
No. of poles	21
Family construction form	M12
Gender	female
Color contact carrier	yellow
Coding	A
No. of poles	5
PIN 1	11
PIN 2	12
PIN 3	21
PIN 4	22
PIN 5	n.c.
Family construction form	M12
Gender	female
Color contact carrier	black
Coding	A
No. of poles	5
PIN 1	13
PIN 2	14
PIN 3	n.c.
PIN 4	n.c.
PIN 5	n.c.