



SIEMENS CONTACTOR SUPPRESSOR

Varistor and LED, 150...250VDC

230 V DC
VDR + LED
For other configurations and voltages, please inquire.

Link do produto

Ilustração

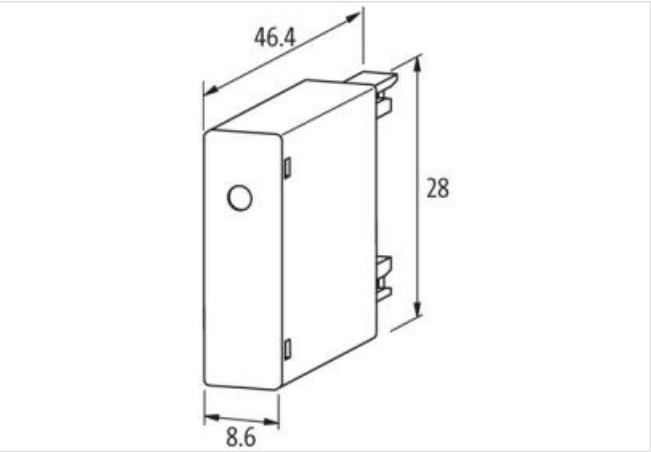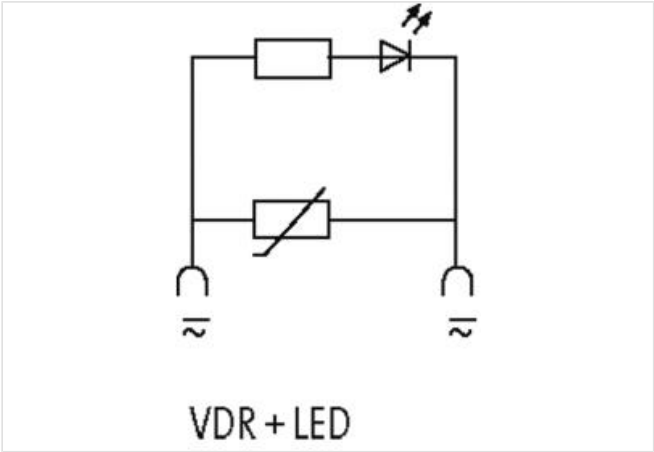

Produto pode diferir da imagem



Dados comerciais	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC002498
Classificação fiscal	85363010
GTIN	4048879010658
Quantidade por embalagem	1
Compatibility Compatible with	
Appropriate contactors	3 RT 20.15/16/17/18
Electrical data	
Damping factor	1.5× UN
Electrical data Input	
Input voltage DC min.	150 V
Input voltage DC max.	250 V
Installation Connection	
Connection information	Plug contact
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Combustibility class housing (UL94)	V-0
Material housing	Plastic
Mechanical data Mounting data	
Height	46,4 mm
Width	28 mm
Depth	8,6 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C