

UNIVERSAL CONTACTOR SUPPRESSOR

RC, 230VAC/DC/25VA/W



230 V AC/DC

RC

For other configurations and voltages, please inquire.
without accessories, can be directly snapped onto DIN-rail, ASA adapter Art.-No. 20900 included.
ASA adapter Art.-No. 20900 (included)

제품 링크

일러스트

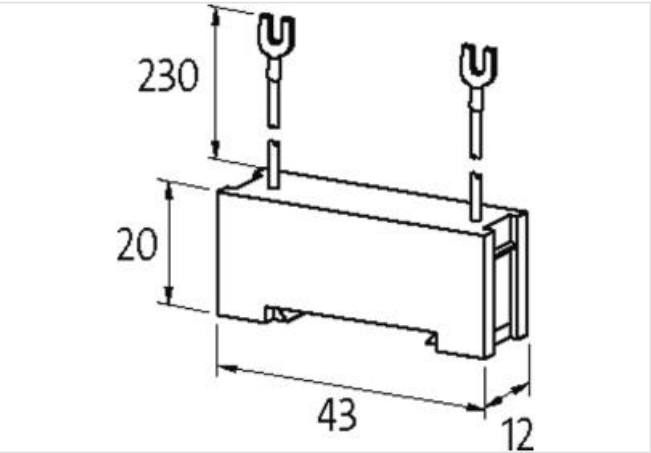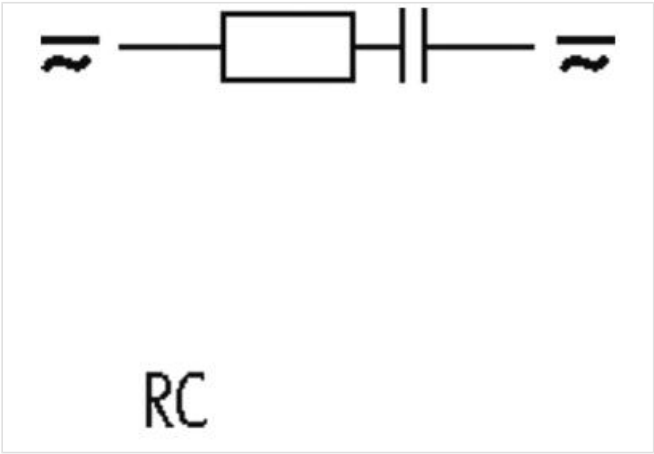

실제 제품은 이미지와 다를 수 있습니다.



제품자료	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013

ECLASS-10.1	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC002498
GTIN	4048879020596
세번부호	85363010
포장단위	1

Compatibility | Compatible with

Appropriate contactors	universal
------------------------	-----------

Electrical data

Holding power max.	25 W
--------------------	------

Electrical data | Input

Input voltage AC min.	110 V
Input voltage AC max.	253 V
Input voltage DC min.	110 V
Input voltage DC max.	253 V

Mechanical data | Mounting data

Height	20 mm
Width	43 mm
Depth	12 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C