



TELEMECANIQUE CONTACTOR SUPPRESSOR

Varistor, 48VAC/DC

24 V AC/DC
48 V AC/DC
VDR
For other configurations and voltages, please inquire.

제품 링크

일러스트

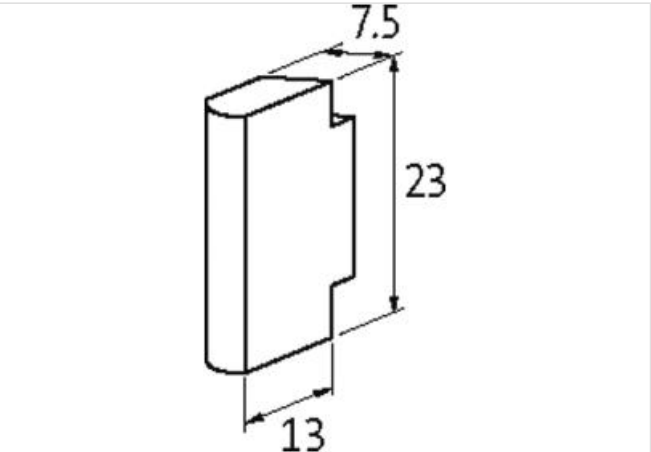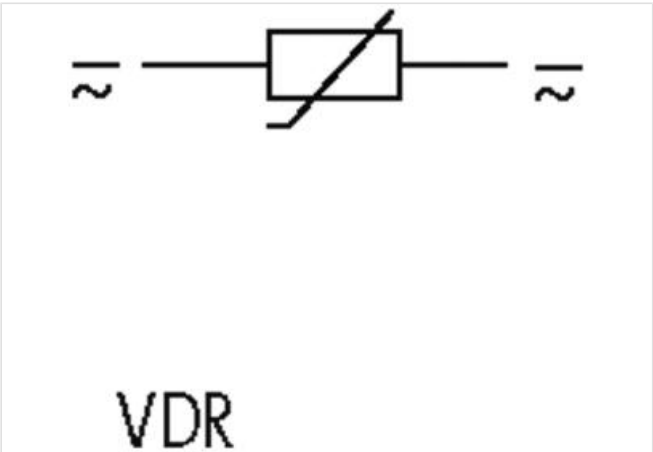

실제 제품은 이미지와 다를 수 있습니다.



제품자료	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC002498
GTIN	4048879018111
세번부호	85363010
포장단위	1
Compatibility Compatible with	
Appropriate contactors	CAWM, M, SC-M
Electrical data	
Damping factor	1.5× UN
Electrical data Input	
Input voltage AC min.	24 V
Input voltage AC max.	53 V
Input voltage DC min.	24 V
Input voltage DC max.	53 V
Installation Connection	
Connection information	Plug contact
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Combustibility class housing (UL94)	V-0
Material housing	Plastic
Mechanical data Mounting data	
Height	13 mm
Width	23 mm
Depth	7,5 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C