

MVP12, 6XM12, 5POLE, PLUGGABLE CABLE

15.0m PUR/PVC 12x0,34+3x0,75


6-way, 5핀
PUR/PVC
15.0 m
디지털 PNP-신호 24 V DC 용 LED 내장

제품 링크

일러스트



M12 Females 5-pole

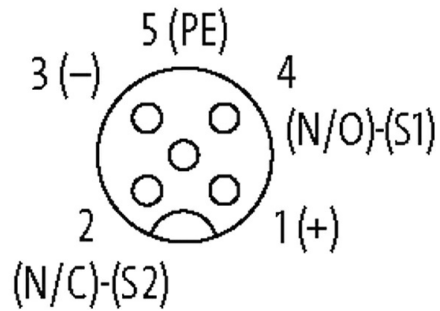

실제 제품은 이미지와 다를 수 있습니다.

인증

cULus

cULus



더보기

Bus technologies

Technical Data

Operating voltage	24 V DC $\pm 25\%$
Operating current per contact	max. 4 A
Protection	IP65 and IP67 when plugged and screwed down (EN 60529)
Material	PBT
Housing	Plastic, flame retardant
Signal per port	2
Total current	max. 8 A

General data

Temperature range	-20...+80 °C
Dimensions H×W×D	125×50.2×17 mm

Cables

No./diameter of wires	12× 0.34 + 3× 0.75 mm ²
Wire isolation	PVC (yebr, rd, grpk, wh, rdbl, gn, whgn, ye, brgn, gr, whye, pk, br, gnye, bl)
C-track properties	2 Mio.
Outer Ø	9.8 mm ±5%
Cable number	388
Color (jacket)	gray
Jacket Color	gray
Temperature range (fixed)	-30...+80 °C
Temperature range (mobile)	-5...+70 °C
Bend radius (fixed)	10× outer Ø
Bend radius (moving)	12× outer Ø
Material (jacket)	PUR/PVC

제품자료

EAN	4048879064477
eClass	27279219
세번부호	85444290
원산지	CZ
포장단위	1.000