

**PASSIVE-DI0° PLASTIC,8XM12,5POL,PRE-WIRED CABLE**

15.0m PUR-JB 16\*0,34+3\*0,75

8-way, 5핀


PUR/PVC

15.0 m


디지털 PNP-신호 24 V DC 용 LED 내장  
다른 케이블 길이가 필요하시면 문의바랍니다.  
화학적 성분 및 오일에 강한 플라스틱 케이스

**제품 링크**

일러스트

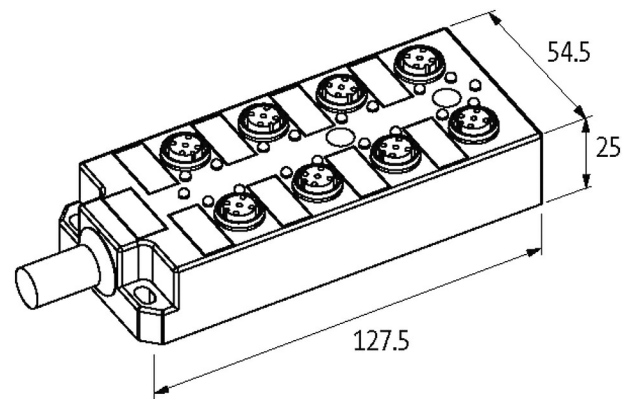

M12 Females 5-pole

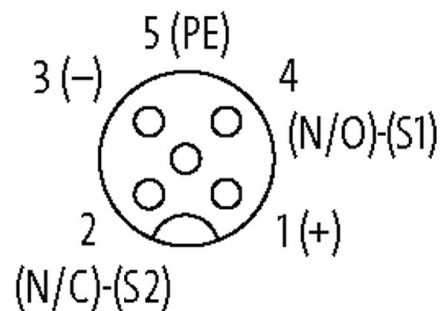

실제 제품은 이미지와 다를 수 있습니다.

**Technical Data**

브로셔에 기재된 정보는 최신정보로 업데이트 되었습니다.

02/21

Operating voltage	24 V DC
Signal per port	2
Operating current per contact	max. 4 A
Total current	max. 10 A
Locking of ports	나사 (M12×1 mm)

**General data**

Dimensions H×W×D	127.5×54.5×25 mm
Protection	IP67 - 커넥터 연결 후 고정시 (EN 60529)
Temperature range	-20...+80 °C

**Cables**

Cable number	398
No./diameter of wires	16× 0.34 + 3× 0.75 mm <sup>2</sup>
Wire isolation	PVC
C-track properties	2 Mio.
Jacket Color	회색
Material (jacket)	PUR/PVC (UL/CSA)
Outer Ø	10.0 mm ±5%
Bend radius (moving)	10× 외경 Ø
Cable identification	398
Cable Type	2 (PUR/PVC)
Approval (cable)	UL (AWM-Style 21441/10955), CE conform
Cable weight [g/m]	165,0
Material (wire)	구리선, 도금하지 않음
Resistor (core)	max. 57 Ω/km (0.34 mm <sup>2</sup> ), max. 26 Ω/km (0.75 mm <sup>2</sup> ); (20 °C)
Single wire Ø (core)	0.15 mm
Construction (core)	19× 0.15 mm (0.34 mm <sup>2</sup> ); 42× 0.15 mm (0.75 mm <sup>2</sup> ); (5/6 등급 멀티코어)
Diameter (core)	16× 0.34 + 3× 0.75 mm <sup>2</sup>
AWG	AWG 22 (0.34 mm <sup>2</sup> ); AWG 19 유사 굵기 (0.75 mm <sup>2</sup> )
Material (wire isolation)	PVC
Material property (wire isolation)	무CFC, 무카드뮴, 무실리콘, 무연
Shore hardness (wire isolation)	43 ±5 D
Wire-Ø incl. isolation	1.3 mm ±5% (0.34 mm <sup>2</sup> ); 1.8 mm ±5% (0.75 mm <sup>2</sup> )
Color/numbering of wires	ws, grs, brgn, ge, wsgn, gn, rtbl, vi, grbr, sw, wsgr, rt, gebr, rs, wsge, gr+bl, br, gnge längsgestreift
Shield	no
Material (jacket)	PUR/PVC
Shore hardness (jacket)	87 ±5 A
Outer-Ø (jacket)	10.0 mm ±5%
Color (jacket)	회색
chemical resistance	양호한 내유성, 내연료성, 내화학성 (EN 60811-404)
Nominal voltage	U0/U 300/300 V AC
Test voltage	2000 V AC
Current load capacity	DIN VDE 0298-4 에 의거
Temperature range (fixed)	-30...+80 °C
Temperature range (mobile)	-5...+60 °C
Bend radius (fixed)	5× 외경 Ø
Bend radius (moving)	10× 외경 Ø
No. of bending cycles (C-track)	max. 2 Mio. (25 °C)
Traversing distance (C-track)	max. 5 m (horizontal)

Travel speed (C-track)	max. 2 m/s
Acceleration (C-track)	max. 10 m/s <sup>2</sup>

**Contact Layout**

PIN 1	(+)
PIN 2	(NC)/(S2)
PIN 3	(-)
PIN 4	(NO)/(S1)
PIN 5	(접지)
LED (녹색): 전원 / LED (황색): (S1/S2)	

**제품자료**

EAN	4048879062909
eClass	27279219
세번부호	85444290
원산지	CZ
포장단위	1