



AMMS 20-47/1 OPTO-COUPLER MODULE

IN: 53 VDC - OUT: 250 VAC / 1 A

Triac 1 A
24 V DC

제품 링크

일러스트

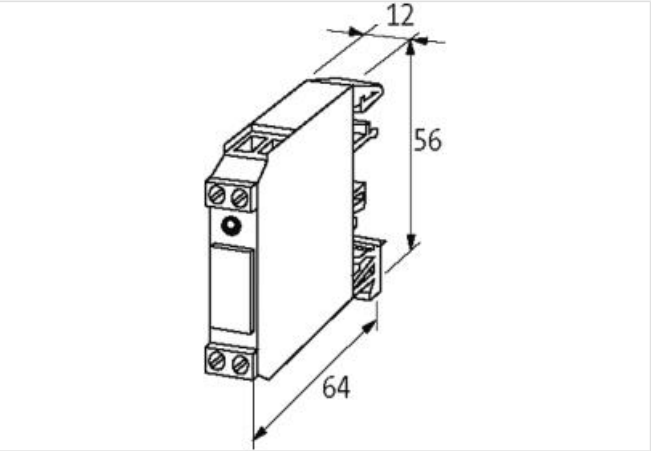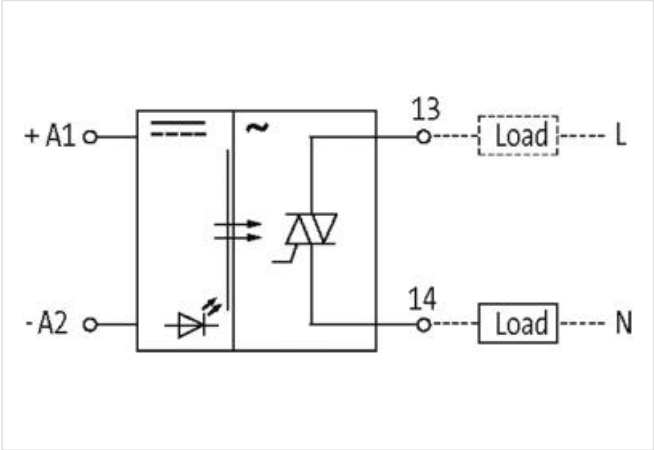

실제 제품은 이미지와 다를 수 있습니다.



제품자료	
ECLASS-6.0	27371604
ECLASS-6.1	27371604
ECLASS-7.0	27371604
ECLASS-8.0	27371604
ECLASS-9.0	27371604
ECLASS-10.1	27371604
ECLASS-11.1	27371604
ECLASS-12.0	27371604

ETIM-5.0	EC001504
GTIN	4048879028073
세번부호	85414900
포장단위	1
Electrical data Input	
Input voltage OFF DC min.	0 V
Input voltage OFF DC max.	3 V
Input voltage DC min.	10 V
Input voltage DC max.	53 V
Input current	6,6 mA
Electrical data Output	
Switch off delay max.	10 ms
Switch on delay max.	10 ms
Quiescent current OFF max.	5 mA
Switching frequency max.	20 Hz
Voltage switching AC min.	24 V
Switching voltage AC max.	253 V
Switching current min.	50 mA
Switching current max.	1 A
Voltage drop AC max.	1,3 V
Diagnostics	
Status indication LED	red
Device protection Electrical	
Rated surge voltage	2,5 kV
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Color housing	black
Material housing	Plastic
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, G32, (EN 60715)
Height	56 mm
Width	12 mm
Depth	64 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C