

UFL 20 L PLUG FOR SIGNAL TRANSFER

24 VDC / 1 A - male with LED




Ribbon cable connector + LED

20-pole


Via the combined fixing mechanism, connectors with or without strain relief can be connected.
for plugs with or without strain relief (DIN 41651); for plugs with strain relief, it may be necessary to remove the bottom hook

제품 링크

일러스트

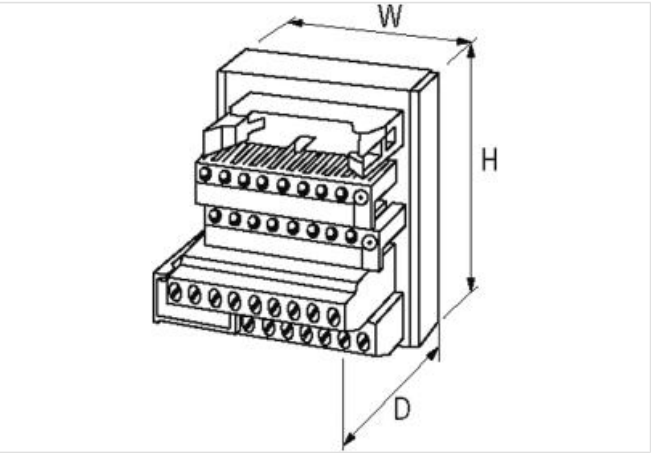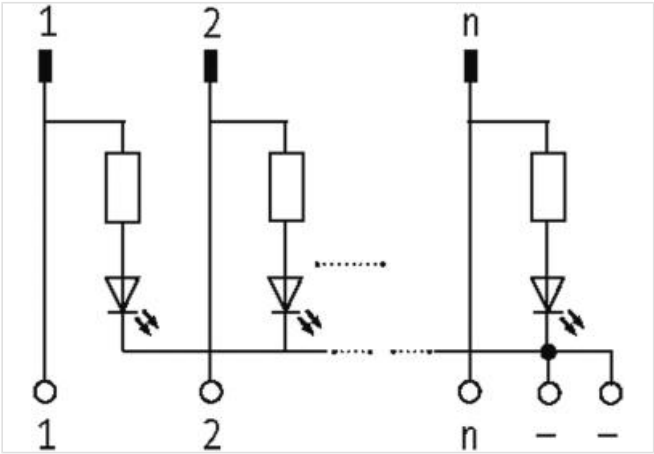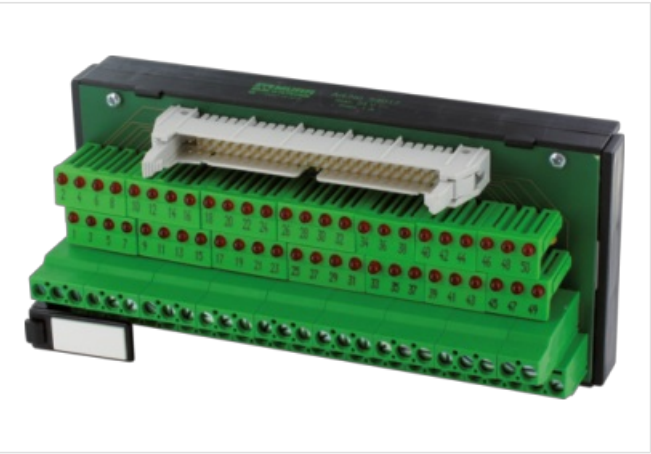

실제 제품은 이미지와 다를 수 있습니다.

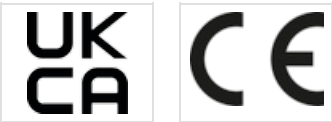

제품자료	
ECLASS-6.0	27141120
ECLASS-6.1	27141120
ECLASS-7.0	27141120
ECLASS-8.0	27141120
ECLASS-9.0	27141120

ECLASS-10.1	27141120
ECLASS-11.1	27141120
ECLASS-12.0	27141120
ETIM-5.0	EC001283
GTIN	4048879026604
세번부호	85366990
포장단위	1

Electrical data | Supply

Operating voltage AC	24 V
Operating current max.	1 A

Diagnostics

Status indication LED	red
-----------------------	-----

Device protection | Electrical

Overvoltage category (EN 60664-1)	II
-----------------------------------	----

Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	63 mm
Width	75 mm
Depth	48 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C