



SV-SUB D 37ST.-KL FOR SIGNAL TRANSFER

125 VAC/DC / 2 A

Male connector  
37-pole  
Screw terminals

제품 링크

일러스트

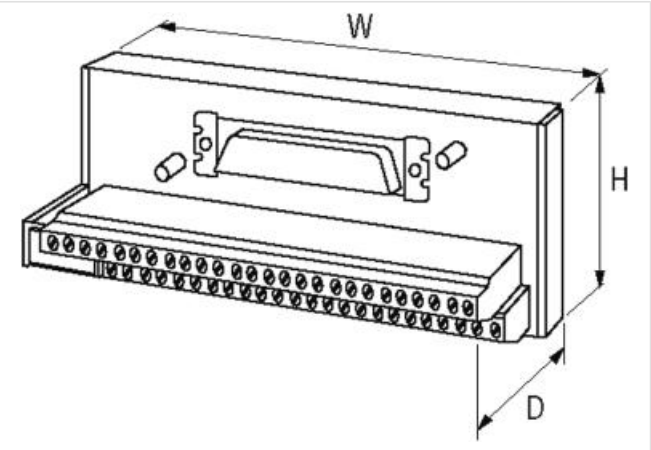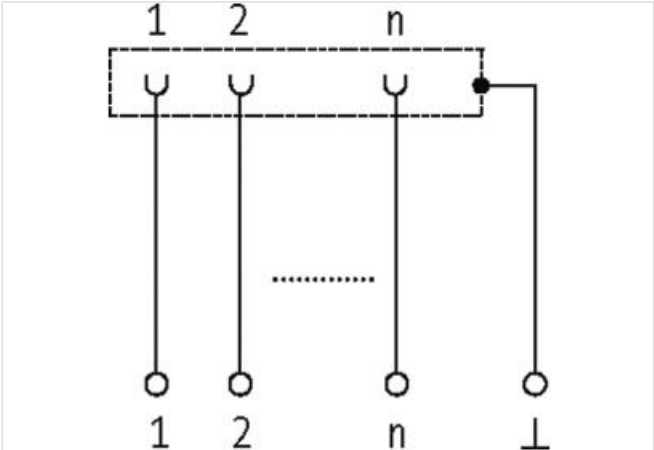

실제 제품은 이미지와 다를 수 있습니다.



| 제품자료        |          |
|-------------|----------|
| ECLASS-6.0  | 27143424 |
| ECLASS-6.1  | 27260708 |
| ECLASS-7.0  | 27141152 |
| ECLASS-8.0  | 27141152 |
| ECLASS-9.0  | 27141152 |
| ECLASS-10.1 | 27141152 |

|                                          |                                                |
|------------------------------------------|------------------------------------------------|
| ECLASS-11.1                              | 27141152                                       |
| ECLASS-12.0                              | 27141152                                       |
| ETIM-5.0                                 | EC001283                                       |
| GTIN                                     | 4048879026512                                  |
| 세번부호                                     | 85366990                                       |
| 포장단위                                     | 1                                              |
| Electrical data   Supply                 |                                                |
| Operating voltage AC                     | 125 V                                          |
| Operating voltage DC                     | 150 V                                          |
| Operating current max.                   | 2 A                                            |
| Device protection   Electrical           |                                                |
| Overvoltage category (EN 60664-1)        | II                                             |
| Mechanical data   Mounting data          |                                                |
| Mounting method                          | geschnappt                                     |
| Suitable for mounting type               | mounting rail, (EN 60715)                      |
| Height                                   | 63 mm                                          |
| Width                                    | 75 mm                                          |
| Depth                                    | 58 mm                                          |
| Looking techniques                       | Standard UNC 4-40 screw thread bolt (EN 60807) |
| Environmental characteristics   Climatic |                                                |
| Operating temperature min.               | -20 °C                                         |
| Operating temperature max.               | 70 °C                                          |