



SV-2 X SUB D 37 -KL. FOR SIGNAL TRANSFER

125 VAC/DC / 2 A

Female connector
37-pole
Screw terminals

제품 링크

일러스트

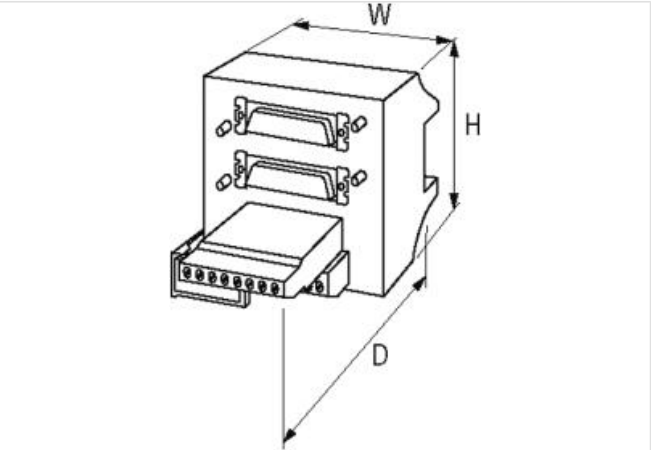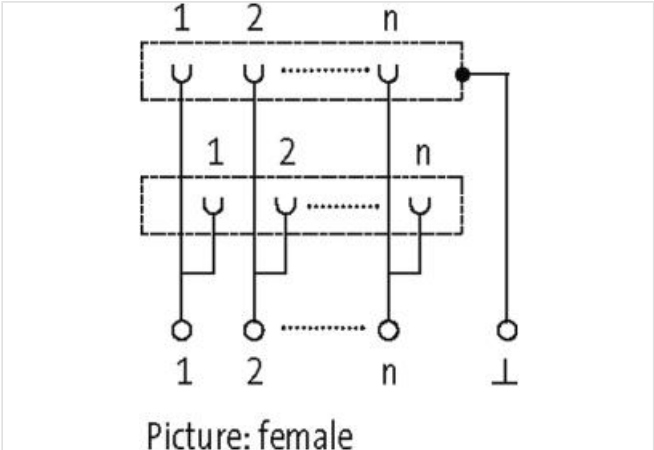

실제 제품은 이미지와 다를 수 있습니다.

제품자료	
ECLASS-6.0	27143424
ECLASS-6.1	27260708
ECLASS-7.0	27141152
ECLASS-8.0	27141152
ECLASS-9.0	27141152
ECLASS-10.1	27141152
ECLASS-11.1	27141152
ECLASS-12.0	27141152
ETIM-5.0	EC001283
GTIN	4048879026192
세번부호	85366990

포장단위	1
Electrical data Supply	
Operating voltage AC	125 V
Operating voltage DC	150 V
Operating current max.	2 A
Device protection Electrical	
Overvoltage category (EN 60664-1)	I
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	86 mm
Width	90 mm
Depth	78 mm
Looking techniques	Standard UNC 4-40 screw thread bolt (EN 60807)
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C