




PKB 1 FOR SIGNAL TRANSFER

250V / 15 A

4× 22-pole
15 A per potential rail
Screw plug-in terminals

제품 링크

일러스트

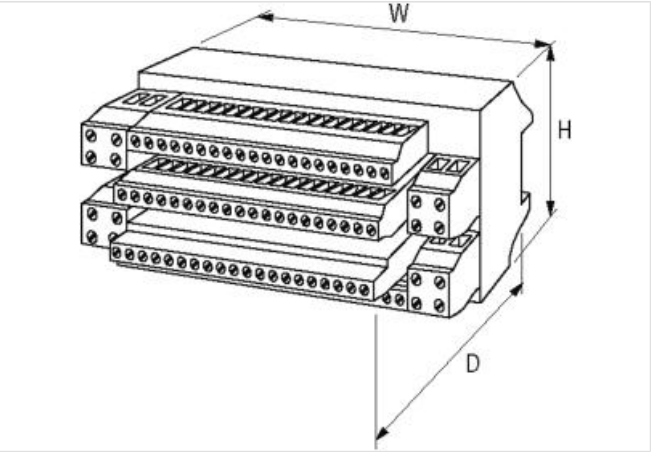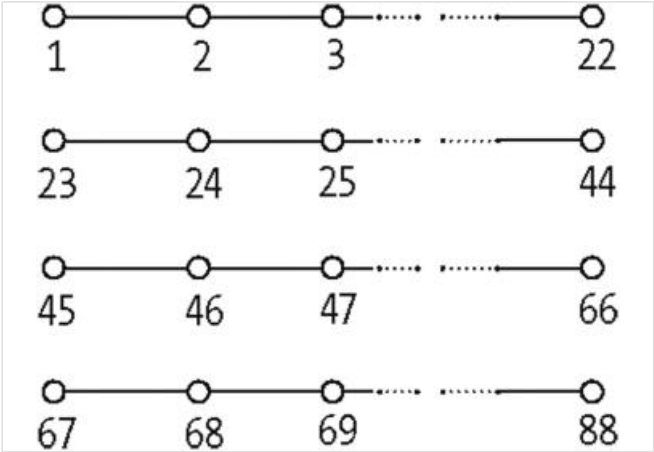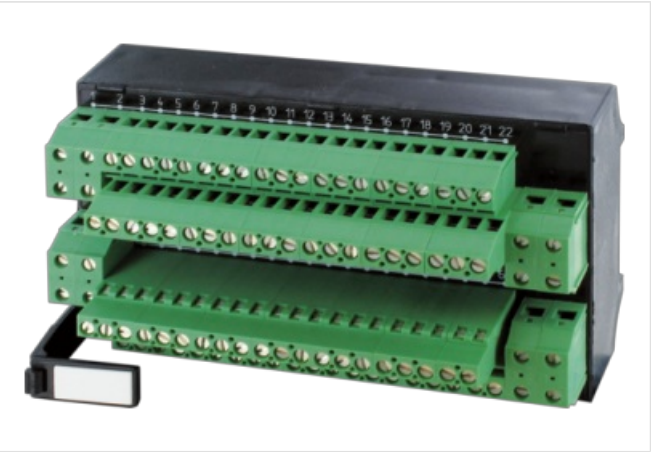

실제 제품은 이미지와 다를 수 있습니다.



제품자료	
ECLASS-6.0	27143424
ECLASS-6.1	27260708
ECLASS-7.0	27141152
ECLASS-8.0	27141152
ECLASS-9.0	27141152
ECLASS-10.1	27141152

ECLASS-11.1	27141152
ECLASS-12.0	27141152
ETIM-5.0	EC001283
GTIN	4048879026062
세번부호	85369010
포장단위	1
Electrical data Supply	
Operating voltage AC	250 V
Total current per potential rail max.	15 A
Installation	
Connection cross-section solid max.	4 mm²
Installation Connection	
Connection	Screw terminals SK
Device protection Electrical	
Overvoltage category (EN 60664-1)	II
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	63 mm
Width	140 mm
Depth	48 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C