




PKB 2 FOR SIGNAL TRANSFER

250V / 25 A

4× 22-pole  
25 A per potential rail  
Screw plug-in terminals  
Input terminal: max. 6 mm<sup>2</sup> single core, total current: max. 100 A

제품 링크

일러스트

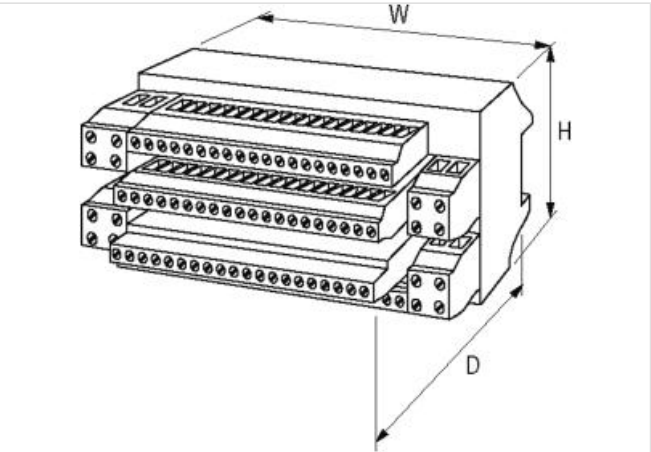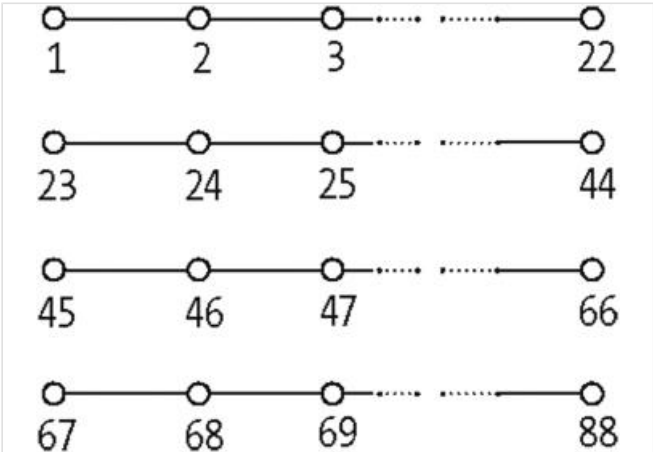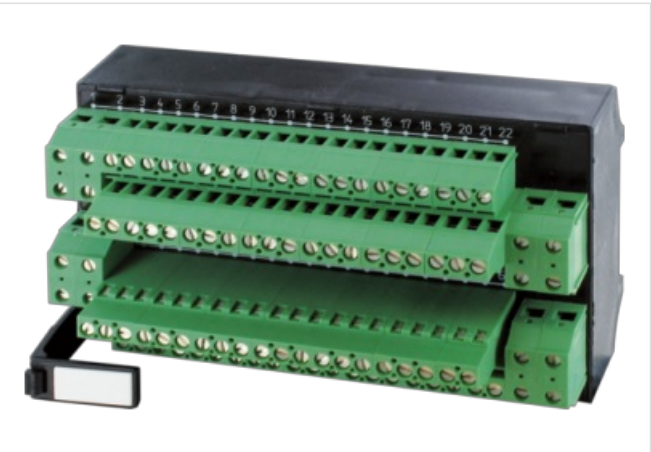

실제 제품은 이미지와 다를 수 있습니다.



| 제품자료        |          |
|-------------|----------|
| ECLASS-6.0  | 27143424 |
| ECLASS-6.1  | 27260708 |
| ECLASS-7.0  | 27141152 |
| ECLASS-8.0  | 27141152 |
| ECLASS-9.0  | 27141152 |
| ECLASS-10.1 | 27141152 |

|                                                      |                           |
|------------------------------------------------------|---------------------------|
| ECLASS-11.1                                          | 27141152                  |
| ECLASS-12.0                                          | 27141152                  |
| ETIM-5.0                                             | EC001283                  |
| GTIN                                                 | 4048879026055             |
| 세번부호                                                 | 85369010                  |
| 포장단위                                                 | 1                         |
| Electrical data   Supply                             |                           |
| Operating voltage AC                                 | 250 V                     |
| Total current per potential rail max.                | 25 A                      |
| Installation                                         |                           |
| Connection cross-section solid max.                  | 6 mm²                     |
| Connection cross-section stranded/fine-stranded max. | 4 mm²                     |
| AWG number                                           | 9                         |
| Installation   Connection                            |                           |
| Connection                                           | Screw terminals SK        |
| Device protection   Electrical                       |                           |
| Overvoltage category (EN 60664-1)                    | II                        |
| Mechanical data   Mounting data                      |                           |
| Mounting method                                      | geschnappt                |
| Suitable for mounting type                           | mounting rail, (EN 60715) |
| Height                                               | 75 mm                     |
| Width                                                | 135 mm                    |
| Depth                                                | 66 mm                     |
| Environmental characteristics   Climatic             |                           |
| Operating temperature min.                           | -20 °C                    |
| Operating temperature max.                           | 60 °C                     |