



MASI67 INSTALLATION TECHNOLOGY

Converter 2x profile cable to 7/8" female

MASI67 converter
2x profile cable to 7/8" (female)
Connection cables are in the online shop under "Connection Technology".

제품 링크

일러스트

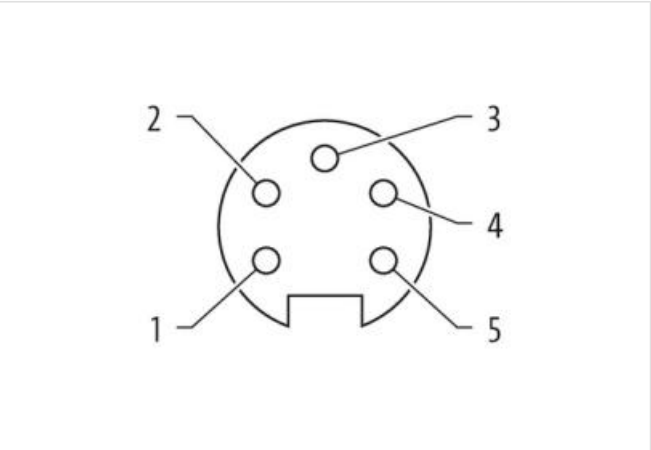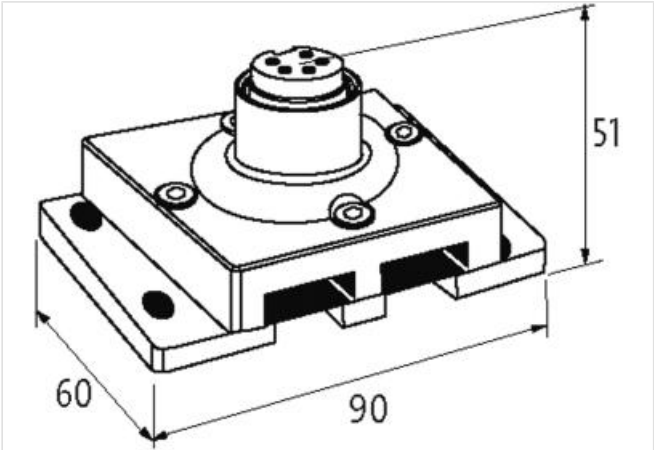

실제 제품은 이미지와 다를 수 있습니다.



제품자료	
ECLASS-6.0	27400209
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440108
ECLASS-10.1	27440111

ECLASS-11.1	27440111
ECLASS-12.0	27440111
ETIM-5.0	EC001583
GTIN	4048879052160
세번부호	85369010
포장단위	1
Electrical data Supply	
Operating voltage DC max.	36 V
Total current max.	8 A
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP67
Insulation strength ASI/Power	200 V
Mechanical data Mounting data	
Mounting method	screwed, geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	90 mm
Width	74 mm
Depth	52 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C
Conformity	
Product standard	EN 60664-1
Connection type 1	
Family construction form	7/8"
Gender	female
Color contact carrier	black
No. of poles	5
PIN 1	AS-i +
PIN 2	AS-i -
PIN 3	n.c.
PIN 4	24 V DC
PIN 5	0 V