




MAI67 INSTALLATION TECHNOLOGY

Converter 2x profile cable to M12 female

MAI67 converter  
2x profile cable to M12 (female)  
Connection cables are in the online shop under "Connection Technology".

제품 링크

일러스트

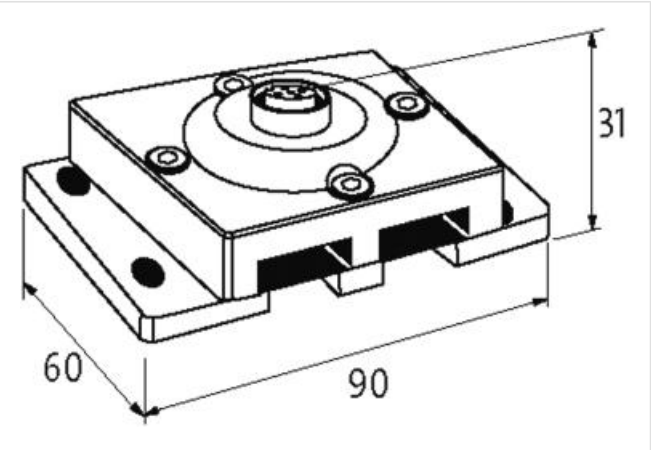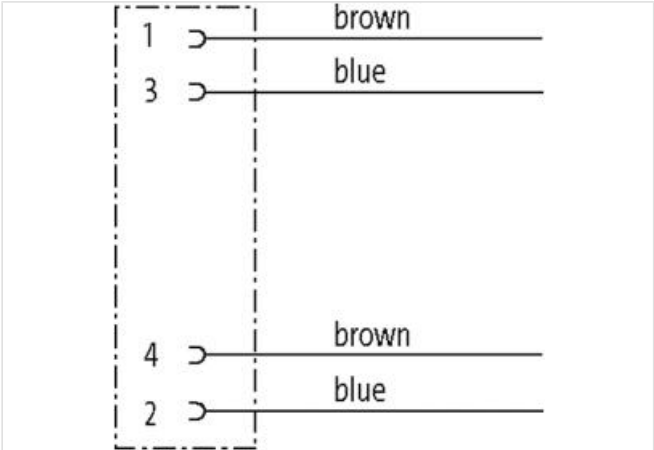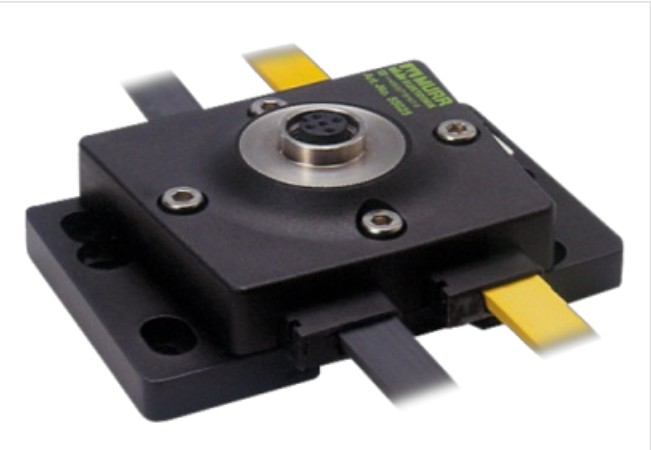

실제 제품은 이미지와 다를 수 있습니다.



| 제품자료        |          |
|-------------|----------|
| ECLASS-6.0  | 27400209 |
| ECLASS-6.1  | 27279219 |
| ECLASS-7.0  | 27279219 |
| ECLASS-8.0  | 27279219 |
| ECLASS-9.0  | 27440108 |
| ECLASS-10.1 | 27440111 |

|             |               |
|-------------|---------------|
| ECLASS-11.1 | 27440111      |
| ECLASS-12.0 | 27440111      |
| ETIM-5.0    | EC001583      |
| GTIN        | 4048879052146 |
| 세번부호        | 85369010      |
| 포장단위        | 1             |

Electrical data | Supply

|                           |      |
|---------------------------|------|
| Operating voltage DC max. | 36 V |
| Total current max.        | 4 A  |

Device protection | Electrical

|                                     |       |
|-------------------------------------|-------|
| Degree of protection (EN IEC 60529) | IP67  |
| Insulation strength ASI/Power       | 200 V |

Mechanical data | Mounting data

|                            |                           |
|----------------------------|---------------------------|
| Mounting method            | screwed, geschnappt       |
| Suitable for mounting type | mounting rail, (EN 60715) |
| Height                     | 90 mm                     |
| Width                      | 74 mm                     |
| Depth                      | 30,5 mm                   |

Environmental characteristics | Climatic

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -20 °C |
| Operating temperature max. | 60 °C  |
| Storage temperature min.   | -40 °C |
| Storage temperature max.   | 80 °C  |

Conformity

|                  |            |
|------------------|------------|
| Product standard | EN 60664-1 |
|------------------|------------|

Connection type 1

|                          |         |
|--------------------------|---------|
| Connection type 1        | Bus Out |
| Family construction form | M12     |
| Gender                   | female  |
| Color contact carrier    | black   |
| Coding                   | A       |
| No. of poles             | 5       |
| PIN 1                    | AS-i +  |
| PIN 2                    | 0 V     |
| PIN 3                    | AS-i -  |
| PIN 4                    | 24 V DC |
| PIN 5                    | n.c.    |