

CUBE20 DIGITAL IN-/OUTPUT MODULE

16 digital inputs and 16 digital outputs


Expansion module
Digital inputs
Digital outputs
DI16/DO16 - (E)

제품 링크

일러스트



실제 제품은 이미지와 다를 수 있습니다.

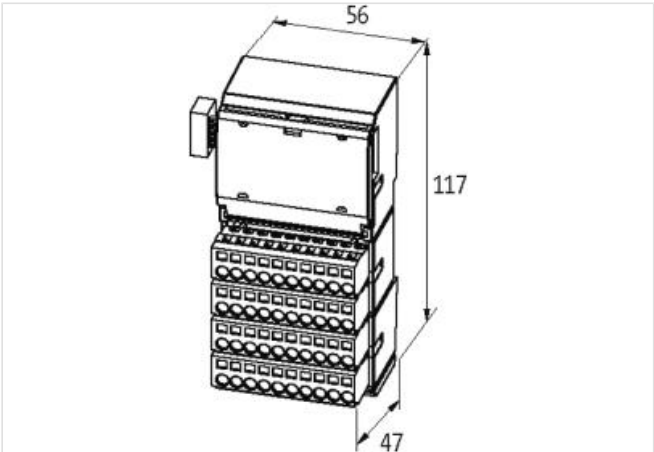

제품자료	
ECLASS-6.0	27242604
ECLASS-6.1	27242604
ECLASS-7.0	27242604
ECLASS-8.0	27242604
ECLASS-9.0	27242604
ECLASS-10.1	27242604
ECLASS-11.1	27242604
ECLASS-12.0	27242604
ETIM-5.0	EC001599
GTIN	4048879049245
세번부호	85176200
포장단위	1
Electrical data Supply	
Norm operating voltage	EN 61131-2
Operating voltage US DC	24 V
Operating voltage UA DC	24 V
Current consumption max.	25 mA
Total current UA max.	12 A
module supply	via system connection
Electrical data Input	

Type input	PNP (EN 61131-2)
Input filter time	1 ms
Current carrying capacity max.	0,7 A
Electrical data Output	
Overload resistant	yes
Short-circuit protected	yes
Output current per pin max.	0,5 A
Lamp load	10 W
Diagnostics	
Diagnostic	Under voltage
Diagnostic via BUS	per module and channel
Diagnostic via LED	per module and channel (only outputs)
Short circuit diagnosis	yes
LED display	Ethernet connection/data traffic
Overload diagnosis	yes
Installation	
Connection cross section max.	2,5 mm ²
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP20
Galvanic separation (operating voltage)	yes
Galvanic separation input/input	yes
Galvanic separation output/output	yes
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	117 mm
Width	56 mm
Depth	47 mm
Environmental characteristics Climatic	
Operating temperature min.	0 °C
Operating temperature max.	55 °C
Storage temperature min.	-20 °C
Storage temperature max.	85 °C
Connection type 4	
Connection type 1	X0
Connection type 2	X1
Connection type 3	X2
Connection type 4	X3
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	colorless
No. of poles	10
PIN 1	DO 0
PIN 2	DO 1
PIN 3	DO 2
PIN 4	DO 3
PIN 5	DO 4
PIN 6	DO 5
PIN 7	DO 6
PIN 8	DO 7

PIN 9	UI
PIN 10	UA
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	colorless
No. of poles	10
PIN 1	DO 8
PIN 2	DO 9
PIN 3	DO 10
PIN 4	DO 11
PIN 5	DO 12
PIN 6	DO 13
PIN 7	DO 14
PIN 8	DO 15
PIN 9	0 V
PIN 10	0 V
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	colorless
No. of poles	10
PIN 1	DIO 0
PIN 2	DIO 1
PIN 3	DIO 2
PIN 4	DIO 3
PIN 5	DIO 4
PIN 6	DIO 5
PIN 7	DIO 6
PIN 8	DIO 7
PIN 9	US
PIN 10	US
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	colorless
No. of poles	10
PIN 1	DI 8
PIN 2	DI 9
PIN 3	DI 10
PIN 4	DI 11
PIN 5	DI 12
PIN 6	DI 13
PIN 7	DI 14
PIN 8	DI 15
PIN 9	0 V
PIN 10	0 V