


CUBE20 AO4 U/I

Expansion module
AO4 - (E) U/I

제품 링크

일러스트

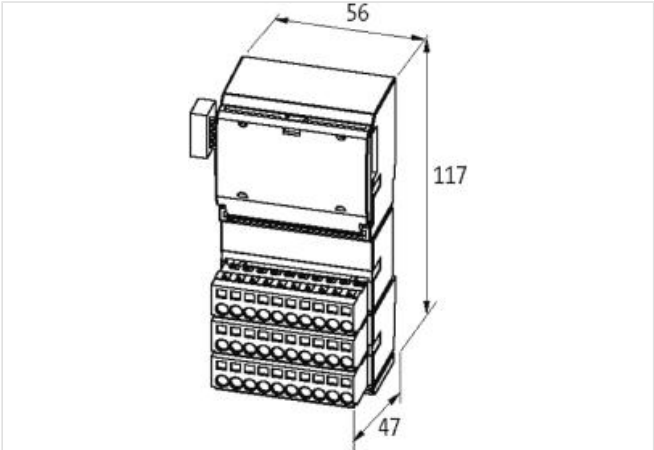

실제 제품은 이미지와 다를 수 있습니다.



제품자료

ECLASS-6.0	27242601
ECLASS-6.1	27242601
ECLASS-7.0	27242601
ECLASS-8.0	27242601
ECLASS-9.0	27242601
ECLASS-10.1	27242601
ECLASS-11.1	27242601
ECLASS-12.0	27242601
ETIM-5.0	EC001596
GTIN	4048879049207
세번부호	85176200
포장단위	1

Electrical data | Supply

Idle current external max.	90 mA
Current consumption max.	25 mA
Total current UA max.	4 A
Total current US max.	4 A
module supply	via system connection

Electrical data | Output

Working resistance max.	60 Ω
Load resistance min.	1 kΩ
Conversion time analog output per channel max	1 ms

Diagnostics

Actuator warning	per channel via LED and BUS
Diagnostic	Under voltage
Diagnostic via BUS	per module and channel
Diagnostic via LED	per module and channel
Short circuit diagnosis	yes
LED display	Ethernet connection/data traffic
Overload diagnosis	yes

Installation

Connection cross section max.	2,5 mm²
-------------------------------	---------

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP20
Galvanic separation (operating voltage)	yes
Galvanic separation input/input	yes

Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	117 mm
Width	56 mm
Depth	47 mm

Environmental characteristics | Climatic

Operating temperature min.	0 °C
Operating temperature max.	55 °C
Storage temperature min.	-20 °C
Storage temperature max.	85 °C

Conformity

Product standard	EN 61131-2
------------------	------------

Connection type 3

Connection type 1	X0
Connection type 2	X1
Connection type 3	X1
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	colorless
No. of poles	10
PIN 1	U 0
PIN 2	I 0
PIN 3	U 1
PIN 4	I 1
PIN 5	U 2
PIN 6	I 2
PIN 7	U 3
PIN 8	I 3
PIN 9	UA
PIN 10	UA
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	colorless
No. of poles	10

PIN 1	0 V
PIN 2	UA 0
PIN 3	0 V
PIN 4	UA 1
PIN 5	0 V
PIN 6	UA 2
PIN 7	0 V
PIN 8	UA 3
PIN 9	0 V
PIN 10	0 V
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	colorless
No. of poles	10
PIN 1	FE
PIN 2	FE
PIN 3	FE
PIN 4	FE
PIN 5	FE
PIN 6	FE
PIN 7	FE
PIN 8	FE
PIN 9	UI
PIN 10	UI