

CUBE67 ACCESSORIES

System interface connector


M12
Female straight
Internal system connection
with mounting socket
Flange, hole spacing 30 mm, bore 3.3 mm

제품 링크

일러스트



실제 제품은 이미지와 다를 수 있습니다.

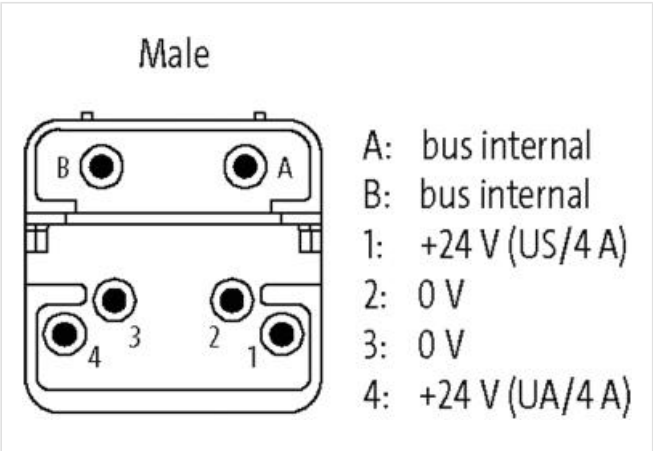

제품자료	
ECLASS-6.0	27242692
ECLASS-6.1	27242692
ECLASS-7.0	27242692
ECLASS-8.0	27242692
ECLASS-9.0	27242692
ECLASS-10.1	27242692
ECLASS-11.1	27242692
ECLASS-12.0	27242692
ETIM-5.0	EC001583
GTIN	4048879047890
세번부호	85366990
포장단위	1
Electrical data Supply	
Operating voltage DC	24 V
Operating current max.	4 A
Installation Connection	
Connection information	Han-Brid®, 6-polig
Family construction form	M12
Gender	female
Mating cycles min.	500
Installation Pin assignment	
No. of poles	6
Device protection Electrical	

Degree of protection (EN IEC 60529) IP65

Mechanical data | Mounting data

Height	80,5 mm
Width	40 mm
Depth	40 mm

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
Operating temperature max.	85 °C