


CUBE20S POTENTIAL DISTRIBUTORS

4 x 24 V DC + 4 x 0 V DC

Potential distributor
Expansion module
4x 24 V DC

제품 링크

일러스트

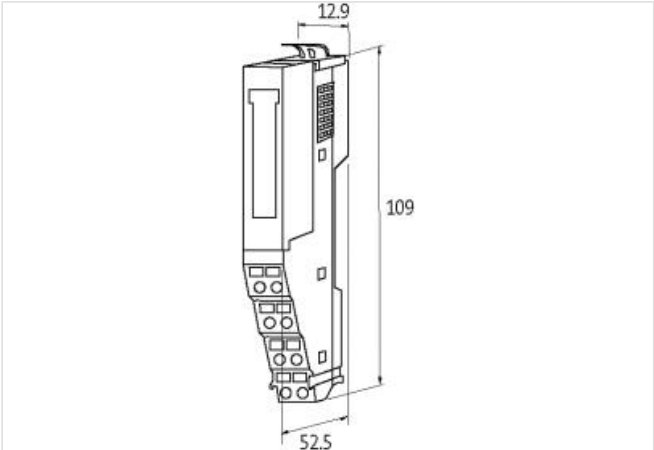

실제 제품은 이미지와 다를 수 있습니다.



제품자료	
ECLASS-6.0	27379201
ECLASS-6.1	27242611
ECLASS-7.0	27242611
ECLASS-8.0	27242611
ECLASS-9.0	27242611
ECLASS-10.1	27242611
ECLASS-11.1	27242611
ECLASS-12.0	27242611
ETIM-5.0	EC001600
GTIN	4048879422871
세번부호	85369010
포장단위	1
Electrical data Supply	
Operating voltage DC max.	30 V
Total current max.	10 A
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP20
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	109 mm

Width	12,9 mm
Depth	52,5 mm
Environmental characteristics Climatic	
Operating temperature min.	0 °C
Operating temperature max.	60 °C
Storage temperature min.	-25 °C
Storage temperature max.	70 °C
Connection type 2	
Connection type 1	Power
Connection type 2	Power
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
No. of poles	8
PIN 1	n.c.
PIN 2	24 V DC
PIN 3	0 V
PIN 4	24 V DC Sys
PIN 5	n.c.
PIN 6	24 V DC
PIN 7	0 V
PIN 8	0 V Sys
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
No. of poles	8
PIN 1	24 V DC
PIN 2	24 V DC
PIN 3	24 V DC
PIN 4	24 V DC
PIN 5	0 V DC
PIN 6	0 V DC
PIN 7	0 V DC
PIN 8	0 V DC