

CUBE20S SSI MODULE

SSI Encoder


RS422

제품 링크

일러스트



실제 제품은 이미지와 다를 수 있습니다.

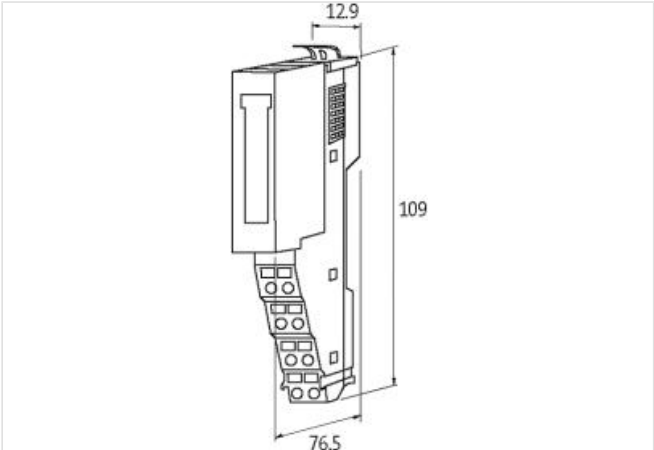

제품자료

ECLASS-6.0	27242605
ECLASS-7.0	27242605
ECLASS-8.0	27242605
ECLASS-9.0	27242605
ETIM-5.0	EC001601
GTIN	4048879422925
세번부호	85389099
포장단위	1

Electrical data | Supply

Current consumption max.	70 mA
module supply	via system connection

Diagnostics

Diagnostic	Under voltage
Diagnostic via BUS	per module
Diagnostic via LED	per module and channel
Short circuit diagnosis	yes
LED display	Ethernet connection/data traffic
Overload diagnosis	yes

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP20
-------------------------------------	------

Mechanical data | Mounting data

Mounting method	geschnappt
-----------------	------------

Suitable for mounting type	mounting rail, (EN 60715)
Height	109 mm
Width	12,9 mm
Depth	76,5 mm

Environmental characteristics | Climatic

Operating temperature min.	0 °C
Operating temperature max.	60 °C
Storage temperature min.	-25 °C
Storage temperature max.	70 °C

Connection type 2

Connection type 1	Power
Connection type 2	Power
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
No. of poles	8
PIN 1	n.c.
PIN 2	24 V DC
PIN 3	0 V
PIN 4	24 V DC Sys
PIN 5	n.c.
PIN 6	24 V DC
PIN 7	0 V
PIN 8	0 V Sys
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
No. of poles	8
PIN 1	CO +
PIN 2	24 V DC
PIN 3	0 V
PIN 4	CI +
PIN 5	CO -
PIN 6	DI +
PIN 7	DI -
PIN 8	CI -