


Tree 8TX IP67 Metal - Unmanaged Switch - 8xM12

8 port unmanaged switch  
Connection cables are in the online shop under "Connection Technology".

제품 링크

일러스트

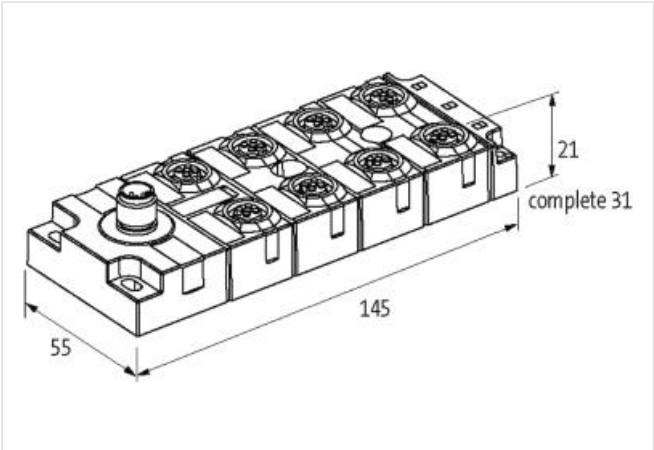

실제 제품은 이미지와 다를 수 있습니다.



| 제품자료                                              |               |
|---------------------------------------------------|---------------|
| ECLASS-6.0                                        | 19170106      |
| ECLASS-6.1                                        | 19170106      |
| ECLASS-7.0                                        | 19170106      |
| ECLASS-8.0                                        | 19170106      |
| ECLASS-9.0                                        | 19170402      |
| ECLASS-10.1                                       | 19170402      |
| ECLASS-11.1                                       | 19170402      |
| ECLASS-12.0                                       | 19170402      |
| ETIM-5.0                                          | EC000734      |
| GTIN                                              | 4048879536509 |
| 세번부호                                              | 85176200      |
| 포장단위                                              | 1             |
| Electrical data   Supply                          |               |
| Operating voltage DC min.                         | 9 V           |
| Operating voltage DC max.                         | 30 V          |
| Industrial communication                          |               |
| Data transmission rate max.                       | 100 MBit/s    |
| Industrial communication   Ethernet functionality |               |
| Auto-crossover                                    | yes           |
| Auto-negotiation                                  | yes           |
| duplex                                            | Full duplex   |
| Switch type                                       | unmanaged     |
| VLAN unmanaged (IEEE 802.1Q)                      | yes           |

Diagnostics

|               |                                  |
|---------------|----------------------------------|
| Alarm contact | no                               |
| Diagnostic    | No voltage                       |
| LED display   | Ethernet connection/data traffic |

Device protection | Electrical

|                                     |      |
|-------------------------------------|------|
| Degree of protection (EN IEC 60529) | IP67 |
|-------------------------------------|------|

Mechanical data | Material data

|                  |                  |
|------------------|------------------|
| Coating housing  | Nickeled         |
| Material housing | Zinc die-casting |

Mechanical data | Mounting data

|                            |                       |
|----------------------------|-----------------------|
| Suitable for mounting type | 4 hole screw mounting |
| Height                     | 145 mm                |
| Width                      | 55 mm                 |
| Depth                      | 31 mm                 |

Environmental characteristics | Climatic

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -25 °C |
| Operating temperature max. | 60 °C  |
| Storage temperature min.   | -40 °C |
| Storage temperature max.   | 80 °C  |

Connection type 2

|                          |                   |
|--------------------------|-------------------|
| Connection type 1        | 4-7               |
| Connection type 2        | Power             |
| Mounting method          | inserted, screwed |
| Tightening torque        | 0,6 Nm            |
| Family construction form | M12               |
| Gender                   | female            |
| Color contact carrier    | black             |
| Coding                   | D                 |
| No. of poles             | 4                 |
| PIN 1                    | TD +              |
| PIN 2                    | RD +              |
| PIN 3                    | TD -              |
| PIN 4                    | RD -              |
| Family construction form | M12               |
| Gender                   | male              |
| Color contact carrier    | black             |
| Coding                   | A                 |
| No. of poles             | 5                 |
| PIN 1                    | 24 V DC (UB 1)    |
| PIN 2                    | 24 V DC (UB 2)    |
| PIN 3                    | 0 V               |
| PIN 4                    | 0 V               |
| PIN 5                    | PE                |