


TREE 6TX ECO - UNMANAGED SWITCH - 6 PORTS

6 port unmanaged switch
Connection cables are in the online shop under "Connection Technology".

제품 링크

일러스트

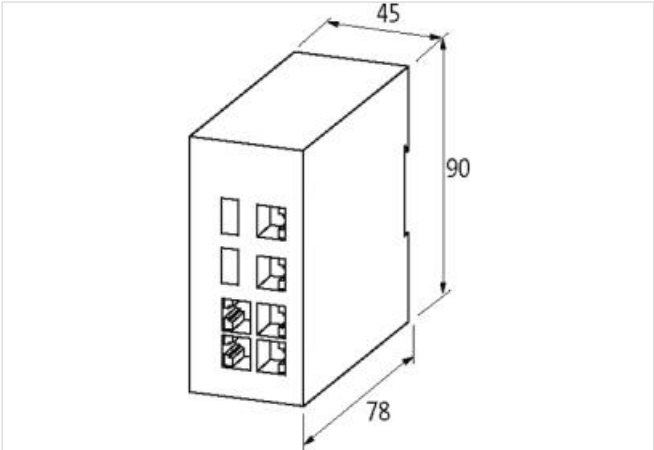

실제 제품은 이미지와 다를 수 있습니다.



제품자료	
ECLASS-6.0	19170106
ECLASS-7.0	19170106
ECLASS-8.0	19170106
ECLASS-9.0	19170106
ETIM-5.0	EC000734
GTIN	4048879329569
세번부호	85176200
포장단위	1
Electrical data Supply	
Operating voltage DC min.	9 V
Operating voltage DC max.	30 V
Industrial communication	
Data transmission rate max.	100 MBit/s
Industrial communication Ethernet functionality	
Auto-crossover	yes
Auto-negotiation	yes
duplex	Full duplex
Switch type	unmanaged
VLAN unmanaged (IEEE 802.1Q)	yes
Diagnostics	
Alarm contact	no
Diagnostic	No voltage

LED display

Ethernet connection/data traffic

Installation Connection	
Number ports	6
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP20
Mechanical data Material data	
Color housing	black
Material housing	Plastic
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715)
Height	90 mm
Width	45,2 mm
Depth	78 mm
Environmental characteristics Climatic	
Operating temperature min.	0 °C
Operating temperature max.	60 °C
Storage temperature min.	-10 °C
Storage temperature max.	70 °C