



IR RELAY SOCKET MODULES

Product discontinued, no alternative

for industrial relays
4 NO/NC contacts
0...230 V AC/DC
without components

제품 링크

일러스트

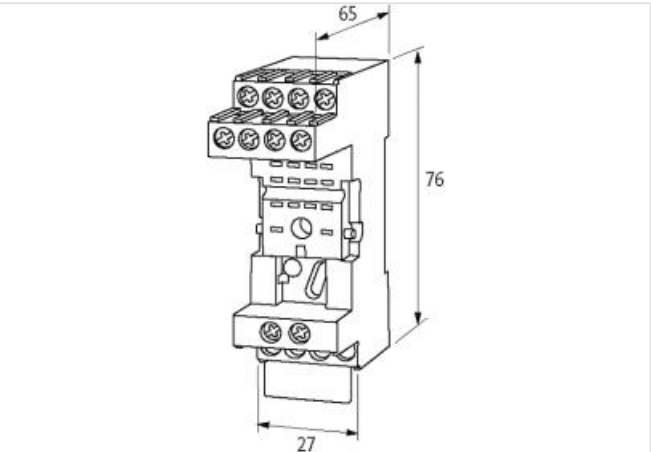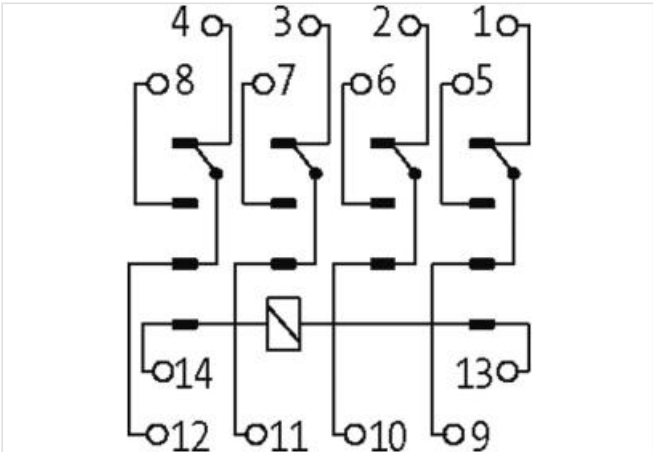

실제 제품은 이미지와 다를 수 있습니다.



제품자료	
ECLASS-6.0	27371603
ECLASS-7.0	27371603
ECLASS-8.0	27371603
ECLASS-9.0	27371603
ETIM-5.0	EC001437
GTIN	4048879025935

세번부호	85366990
포장단위	1
Electrical data Output	
Switching voltage AC max.	250 V
Switching voltage DC max.	110 V
Switching current max.	5 A
Installation Connection	
Connection	Spring clamp terminals FK
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP40
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	76,5 mm
Width	27 mm
Depth	65 mm