


ASSEMBLY MODULE MP 6 S

Mounting rail / screw-type terminal

6 pairs of solder pins
screw terminals connected to solder pin pairs

제품 링크

일러스트

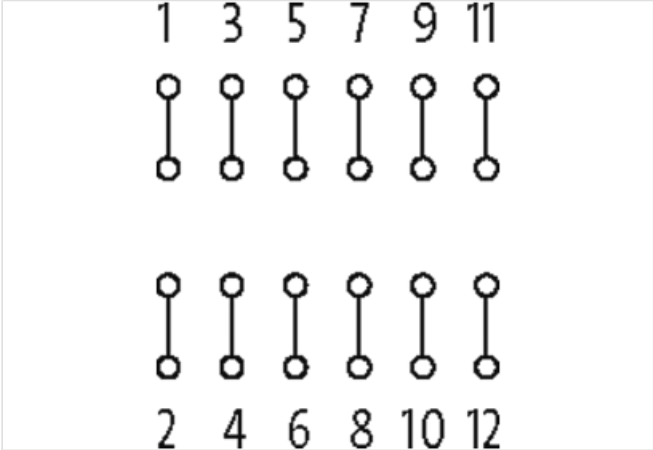

실제 제품은 이미지와 다를 수 있습니다.

제품자료	
ECLASS-6.0	27260710
ECLASS-6.1	27141149
ECLASS-7.0	27141149
ECLASS-8.0	27141149
ECLASS-9.0	27141149
ECLASS-10.1	27141149
ECLASS-11.1	27141149
ECLASS-12.0	27141149
ETIM-5.0	EC002780
GTIN	4048879042239
세번부호	85369010
포장단위	1

Electrical data Supply	
Operating voltage AC max.	250 V
Operating voltage DC max.	250 V
Operating current max.	5 A
Installation	
Connection cross section max.	4 mm²
Installation Connection	
Connection	Screw terminals SK
Connection information	Lötstützpunktpaare (Raster 5 mm)
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Housing properties	open design
Material housing	Plastic
Mechanical data Mounting data	
Distance of solder pins	50 mm
Mounting method	screwed, geschnappt
Suitable for mounting type	Mounting rail TH35, G32, (EN 60715)
Height	63 mm
Width	90 mm
Depth	36 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C