

EUROCARD HOLDER

SKP 32/1 F, 250V/4A, row b,z

Screw terminals

32-pole F (EN 60603)

Row b, z

250 V AC



With the vertical snap adapter SASA 135 Art.-No. 63900 the holder can be mounted at right-angles on the rail.

The D2 size is for a card without a front plate.

To insert the card first press down the 2 yellow buttons. Then slide the Eurocard into the guide slots pushing until fully engaged. The card is now locked into position. It can be removed by pressing down on the 2 yellow buttons.

제품 링크

일러스트

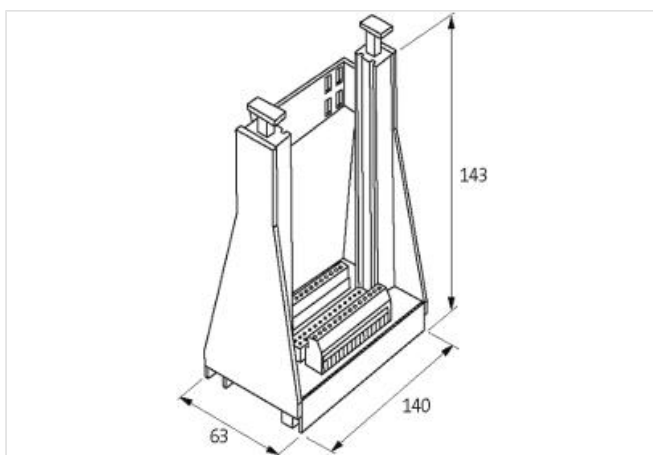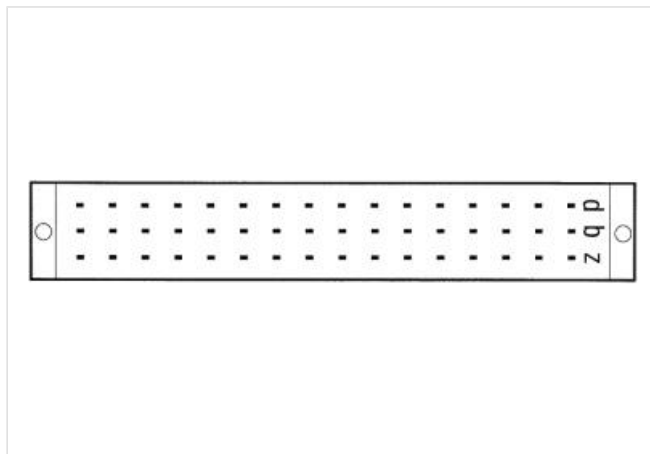

실제 제품은 이미지와 다를 수 있습니다.



제품자료

ECLASS-6.0	27260710
ECLASS-6.1	27260704

ECLASS-7.0	27440402
ECLASS-8.0	27440402
ECLASS-9.0	27440402
ECLASS-10.1	27440402
ECLASS-11.1	27460201
ECLASS-12.0	27460201
ETIM-5.0	EC002780
GTIN	4048879042192
세번부호	85366990
포장단위	1
Electrical data Supply	
Operating voltage AC	250 V
Operating current max.	4 A
Installation	
Connection cross-section solid max.	4 mm²
Installation Pin assignment	
No. of poles	32
Device protection Electrical	
Overvoltage category (EN 60664-1)	I
Device protection Media	
Flame resistance	flame retardant
Mechanical data	
Type of socket connector	F (EN 60603)
Mechanical data Material data	
Material housing	Plastic
Mechanical data Mounting data	
Mounting method	screwed, geschnappt
Suitable for mounting type	mounting rail, (EN 60715)