



MKS-D 10/1300-1 P DIODE MODULES

Mounting rail / screw-type terminal

10 diodes
Common potential cathode

제품 링크

일러스트

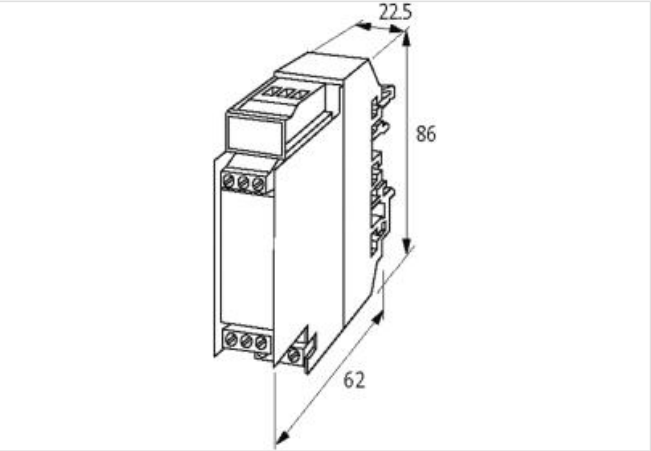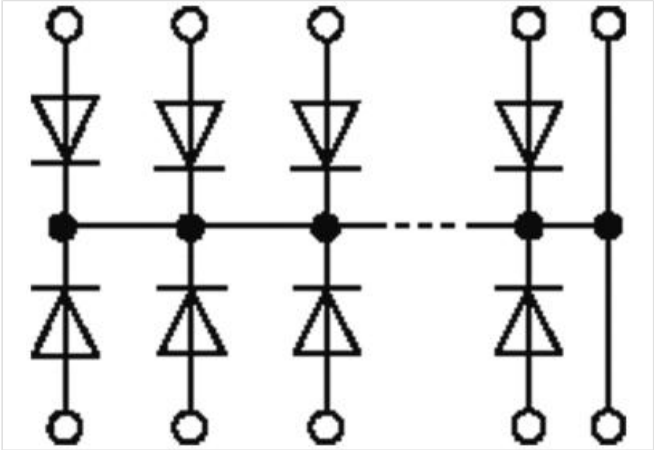

실제 제품은 이미지와 다를 수 있습니다.



제품자료	
ECLASS-6.0	27371010
ECLASS-6.1	27371010
ECLASS-7.0	27371010
ECLASS-8.0	27371010
ECLASS-9.0	27371010
ECLASS-10.1	27371010
ECLASS-11.1	27371010
ECLASS-12.0	27371010

ETIM-5.0	EC002780
GTIN	4048879041935
세번부호	85411000
포장단위	1
Electrical data Supply	
Operating voltage AC max.	48 V
Operating voltage DC max.	48 V
Installation	
Connection cross section max.	4 mm²
Installation Connection	
Connection	Screw terminals SK
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, G32, (EN 60715)
Height	86 mm
Width	22,5 mm
Depth	62 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Connection type 1	
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
No. of poles	12