



MKS-LDP 5/1300 - 1 M DIODE MODULES

Mounting rail / screw-type terminal

Universal diode 1 300 V, 1 A
5 pair of diodes
Common potential anode
Pairs of joined diodes with common control for lamp test

제품 링크

일러스트

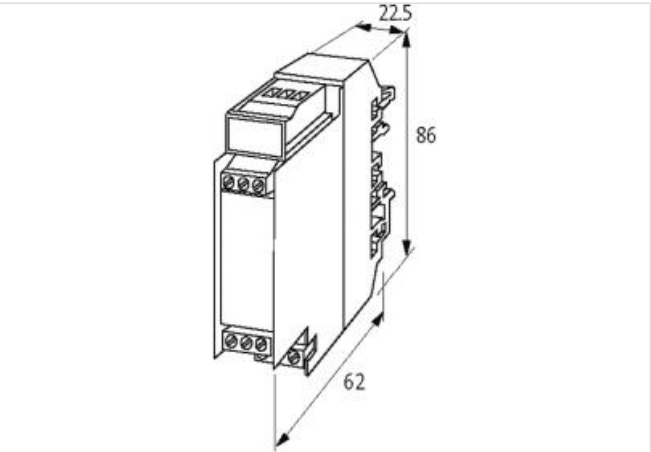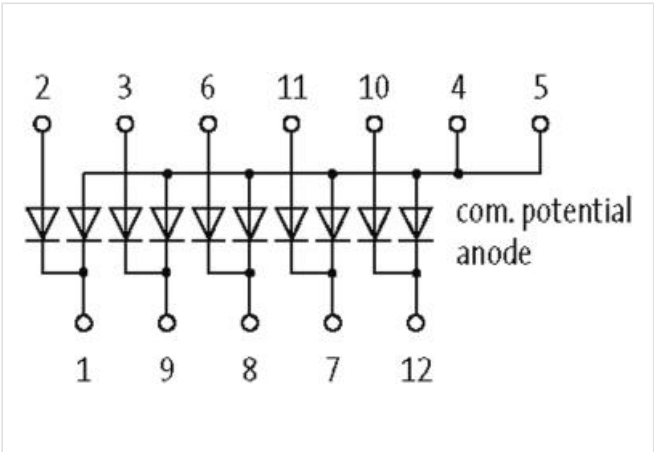

실제 제품은 이미지와 다를 수 있습니다.



제품자료	
ECLASS-6.0	27371010
ECLASS-6.1	27371010
ECLASS-7.0	27371010
ECLASS-8.0	27371010
ECLASS-9.0	27371010
ECLASS-10.1	27371010

ECLASS-11.1	27371010
ECLASS-12.0	27371010
ETIM-5.0	EC002780
GTIN	4048879041843
세번부호	85411000
포장단위	1

Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, G32, (EN 60715)
Height	86 mm
Width	22,5 mm
Depth	62 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C

Connection type 1

Connection	Screw terminals SK
Family construction form	terminal
Gender	female
No. of poles	12