

MSVD POWER SOCKET NEMA

Mounting rail

USA (2× NEMA 5-20)

Screw terminals


Each socket can be loaded with 20 A, however, the total load of both sockets must be below 30 A.

제품 링크

일러스트



실제 제품은 이미지와 다를 수 있습니다.

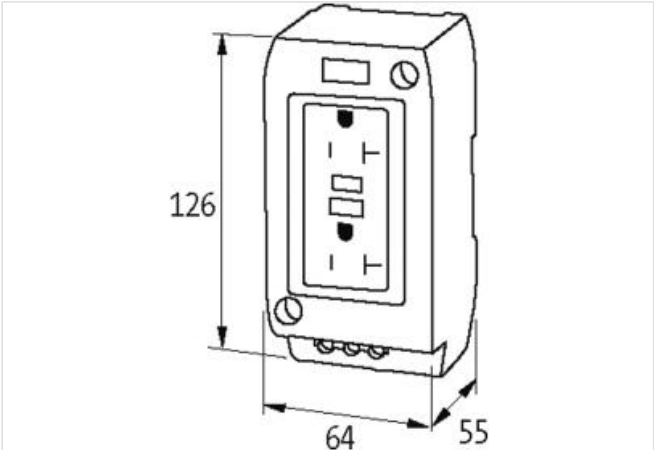

제품자료	
ECLASS-6.0	27189217
ECLASS-6.1	27142305
ECLASS-7.0	27142305
ECLASS-8.0	27142305
ECLASS-9.0	27142305
ECLASS-10.1	27142305
ECLASS-11.1	27142305
ECLASS-12.0	27142305
ETIM-5.0	EC000020
GTIN	4048879041362
세번부호	85366990
포장단위	1
Electrical data Supply	
Operating voltage AC	125 V
Operating current max.	20 A
Installation	
Connection cross section max.	6 mm²
Installation Connection	
Connection	Screw terminals SK
Mechanical data Mounting data	

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	126 mm
Width	64 mm
Depth	55 mm