

Reset button with 2 illuminated push buttons

Every 1 NO contact in a IP65 enclosure

R-Button / 42 2NO L M12(8)

with M12 connection

8-pole

2 buttons can be lit (each 1 NO contact)

Delivery contents:




Flat lens, transparent clear, red, yellow, green, blue

Label plates, O, I, R, ↑, ↓

mounting with clip on the back side

제품 링크

일러스트

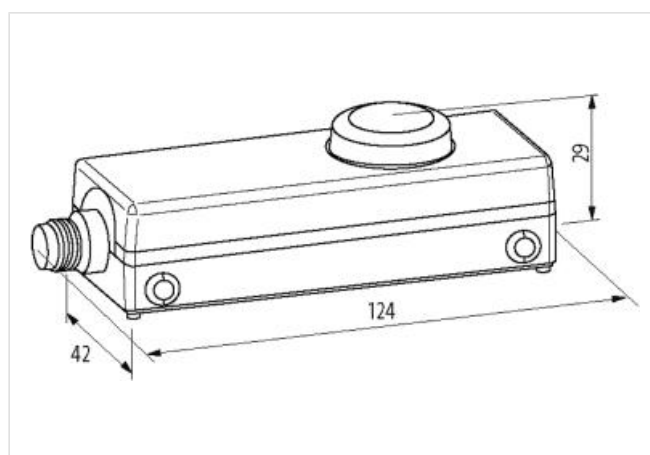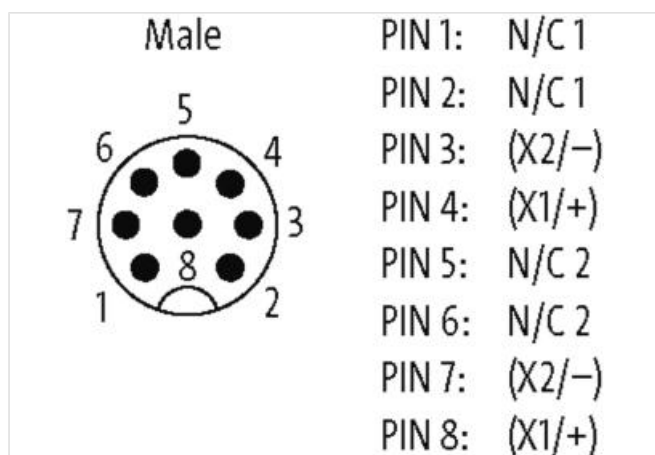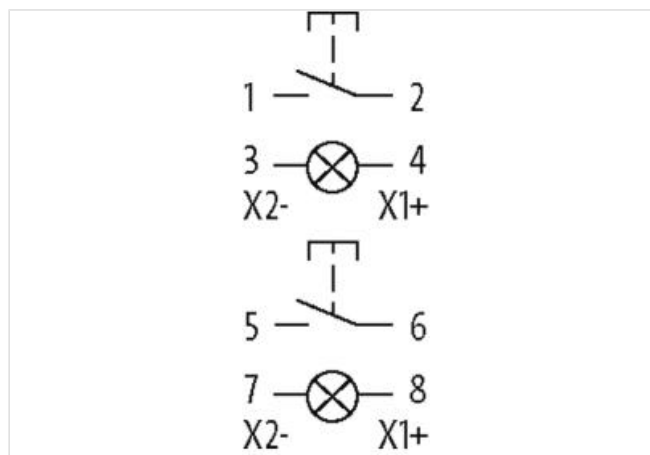

실제 제품은 이미지와 다를 수 있습니다.



제품자료

ECLASS-6.0	27371228
ECLASS-6.1	27371228

ECLASS-7.0	27371228
ECLASS-8.0	27371228
ECLASS-9.0	27371228
ECLASS-10.1	27371228
ECLASS-11.1	27371228
ECLASS-12.0	27371228
ETIM-5.0	EC000225
GTIN	4048879594325
세번부호	85365080
포장단위	1
Electrical data	
Operating voltage AC/DC LED illumination max.	30 V
Operating current LED illumination	14 mA @24 V DC
Electrical data Supply	
Operating voltage DC min.	1 V
Operating voltage DC max.	36 V
Operating voltage DC (UL Recognized)	30 V
Operating current	1,5 A
Device protection	
Condition lifetime	load-dependent, temperature dependent
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP65
Electrical lifetime	1000000 Cycles
Device protection Mechanical	
Mechanical endurance	1000000 Cycles
Mechanical data	
Bounce time max.	10 ms
Mechanical data Material data	
Material contact	AgNi
Mechanical data Mounting data	
Height	29 mm
Width	124 mm
Depth	42 mm
Environmental characteristics Climatic	
Operating temperature min.	-25 °C
Operating temperature max.	70 °C
Storage temperature min.	-25 °C
Storage temperature max.	85 °C
Connection type 1	
Family construction form	M12
Gender	male
Color contact carrier	black
Coding	A
No. of poles	8
PIN 1	NO 1
PIN 2	NO 1
PIN 3	X 2 -
PIN 4	X 1 +
PIN 5	NO 2

PIN 6	NO 2
PIN 7	X 2 -
PIN 8	X 1 +