

LED-INDICATOR OPAC / RED

LED-110V IP65


(red)
110 V AC/DC
The modules are suitable for wall thickness of 1.5...5.0 mm.

제품 링크

일러스트



실제 제품은 이미지와 다를 수 있습니다.

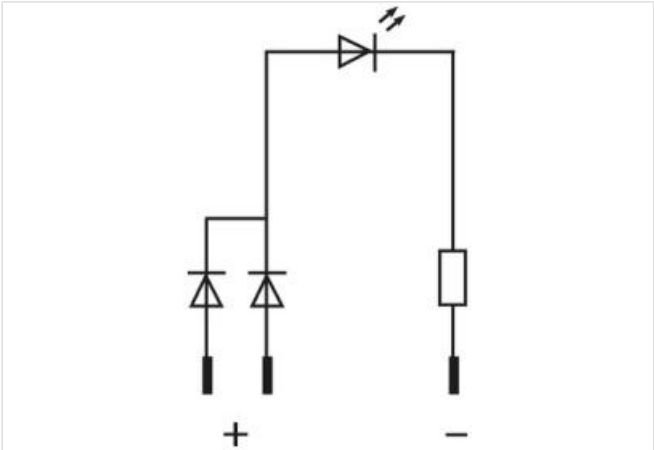

제품자료

ECLASS-6.0	27261590
ECLASS-6.1	27261501
ECLASS-7.0	27261501
ECLASS-8.0	27261501
ECLASS-9.0	27261501
ECLASS-10.1	27261501
ECLASS-11.1	27261501
ECLASS-12.0	27261501
ETIM-5.0	EC000272
GTIN	4048879041324
세번부호	85318070
포장단위	10

Electrical data | Supply

Operating voltage AC	110 V
Operating voltage AC min.	95 V
Operating voltage AC max.	121 V
Operating voltage DC	110 V
Operating voltage DC min.	95 V
Operating voltage DC max.	121 V
Current consumption min.	8 mA
Current consumption max.	12 mA

Installation | Connection

Connection information	Faston 2.8×0.8 mm
------------------------	-------------------

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65
-------------------------------------	------

Flame resistance flame retardant

Diameter LED	5 mm
--------------	------

Material housing	Plastic
------------------	---------

Diameter front panel drilling	9 mm
-------------------------------	------

Operating temperature min. -20 °C

Operating temperature max.	50 °C
----------------------------	-------