



LED-INDICATOR YELLOW

LED 10mm - 24V DC - 20 mA - IP67

(yellow)
24 V DC

제품 링크

일러스트

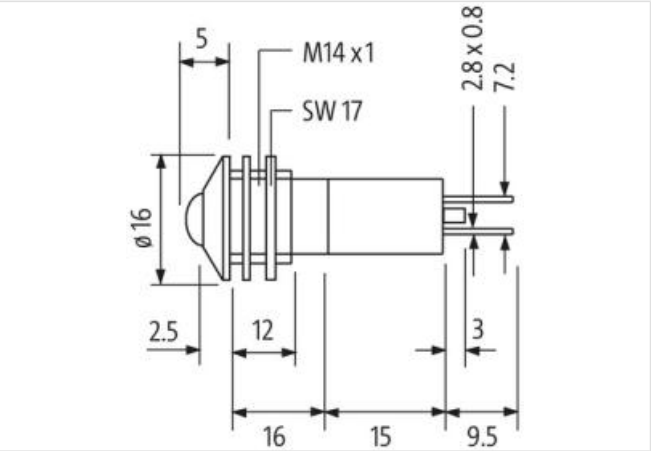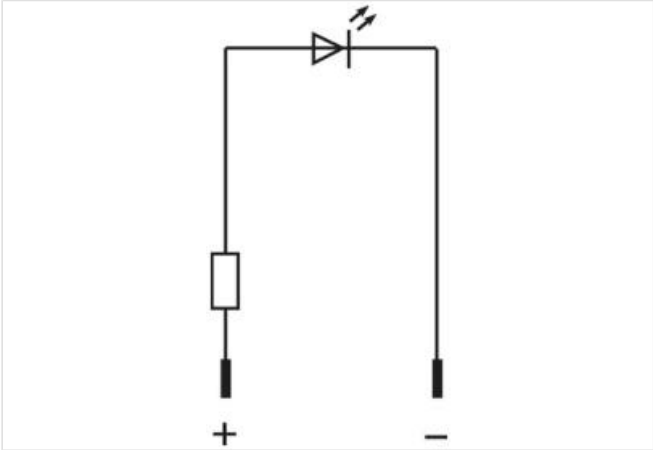

실제 제품은 이미지와 다를 수 있습니다.

제품자료	
ECLASS-6.0	27261590
ECLASS-6.1	27261501
ECLASS-7.0	27261501
ECLASS-8.0	27261501
ECLASS-9.0	27261501
ECLASS-10.1	27261501
ECLASS-11.1	27261501
ECLASS-12.0	27261501
ETIM-5.0	EC000272
GTIN	4048879041157
세번부호	85318070
포장단위	10

Electrical data | Supply

Operating voltage DC	24 V
Operating voltage DC min.	20,4 V
Operating voltage DC max.	26,4 V
Current consumption max.	15 mA

Installation | Connection

Connection information	Faston 2.8×0.8 mm
------------------------	-------------------

Mechanical data | Material data

Coating housing	chrome-plated
Material housing	Brass

Mechanical data | Mounting data

Height	16 mm
Width	16 mm
Depth	45 mm

Environmental characteristics | Climatic

Operating temperature min.	-30 °C
Operating temperature max.	75 °C