



LED-INDICATOR GREEN

LED 5mm - 24V AC/DC - 15mA - IP40

(green)  
24 V AC/DC  
Protection IP40

제품 링크

일러스트

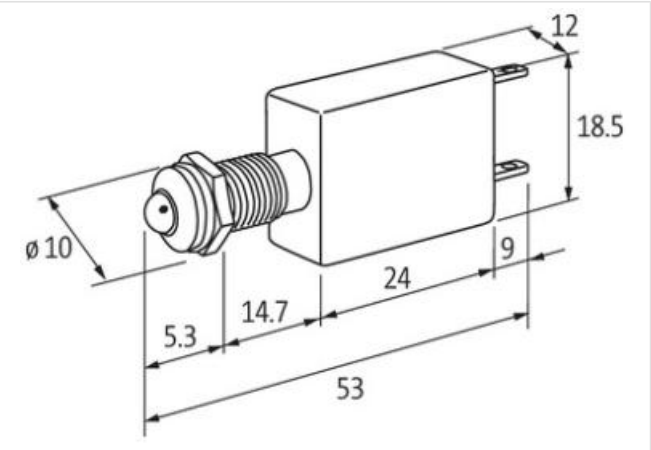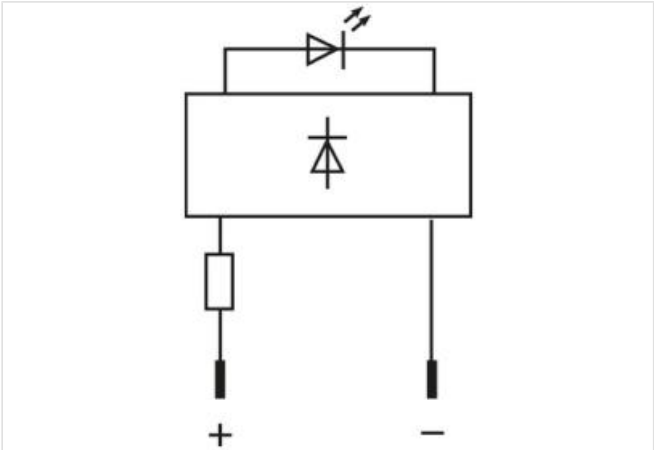

실제 제품은 이미지와 다를 수 있습니다.

| 제품자료        |               |
|-------------|---------------|
| ECLASS-6.0  | 27261590      |
| ECLASS-6.1  | 27261501      |
| ECLASS-7.0  | 27261501      |
| ECLASS-8.0  | 27261501      |
| ECLASS-9.0  | 27261501      |
| ECLASS-10.1 | 27261501      |
| ECLASS-11.1 | 27261501      |
| ECLASS-12.0 | 27261501      |
| ETIM-5.0    | EC000272      |
| GTIN        | 4048879040990 |
| 세번부호        | 85318070      |

|                                          |                   |
|------------------------------------------|-------------------|
| 포장단위                                     | 10                |
| Electrical data   Supply                 |                   |
| Operating voltage AC                     | 24 V              |
| Operating voltage AC min.                | 20,4 V            |
| Operating voltage AC max.                | 26,4 V            |
| Operating voltage DC                     | 24 V              |
| Operating voltage DC min.                | 20,4 V            |
| Operating voltage DC max.                | 26,4 V            |
| Current consumption min.                 | 13 mA             |
| Current consumption max.                 | 17 mA             |
| Installation   Connection                |                   |
| Connection information                   | Faston 2.8x0.8 mm |
| Device protection   Electrical           |                   |
| Degree of protection (EN IEC 60529)      | IP40              |
| Mechanical data                          |                   |
| Diameter LED                             | 5 mm              |
| Mechanical data   Material data          |                   |
| Color housing                            | gray              |
| Material housing                         | PVC               |
| Mechanical data   Mounting data          |                   |
| Diameter front panel drilling            | 8 mm              |
| Height                                   | 18,5 mm           |
| Width                                    | 12 mm             |
| Depth                                    | 53 mm             |
| Environmental characteristics   Climatic |                   |
| Operating temperature min.               | -40 °C            |
| Operating temperature max.               | 70 °C             |