



LED-display 230V AC blue

Product discontinued, no alternative

(blue)
230 V AC/DC
Protection IP40

제품 링크

일러스트

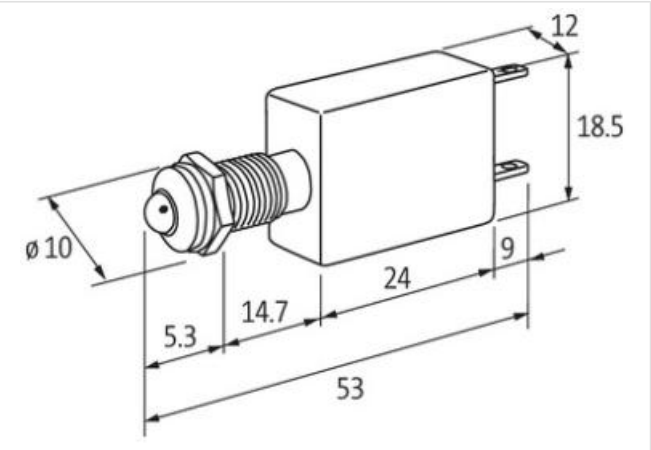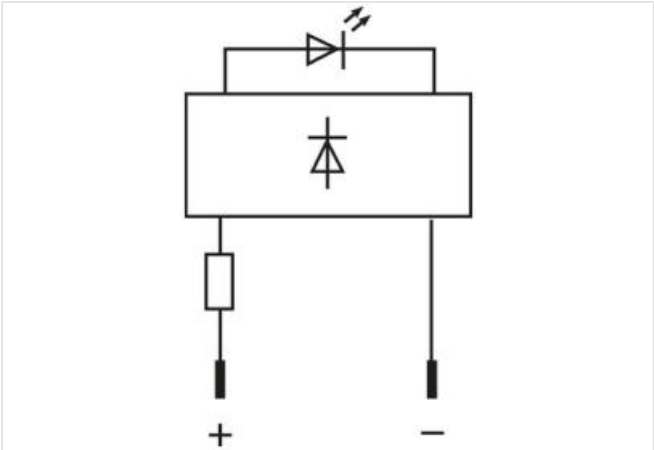

실제 제품은 이미지와 다를 수 있습니다.

제품자료	
ECLASS-6.0	27261590
ECLASS-7.0	27261590
ECLASS-8.0	27261590
ECLASS-9.0	27261590
ETIM-5.0	EC000272
GTIN	4048879040945
세번부호	85318070
포장단위	10
Electrical data Supply	
Operating voltage AC	230 V
Operating voltage AC min.	207 V

Operating voltage AC max.	253 V
Current consumption min.	4,5 mA
Current consumption max.	5,5 mA
Installation Connection	
Connection information	Faston 2.8×0.8 mm
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP40
Mechanical data	
Diameter LED	5 mm
Mechanical data Material data	
Color housing	gray
Material housing	PVC
Mechanical data Mounting data	
Diameter front panel drilling	8 mm
Height	18,5 mm
Width	12 mm
Depth	53 mm
Environmental characteristics Climatic	
Operating temperature min.	-40 °C
Operating temperature max.	70 °C