


MTPS POWER SUPPLY 1/2-PHASE, SMOOTHED

IN: 230/400+/-15VAC OUT: :24V/2ADC

The MTPS series comprises single-/two-phase power supplies/rectified power supply units, incorporating safety isolating transformers, with protection class I and protection degree IP20 for general use in industrial applications.

제품 링크

일러스트

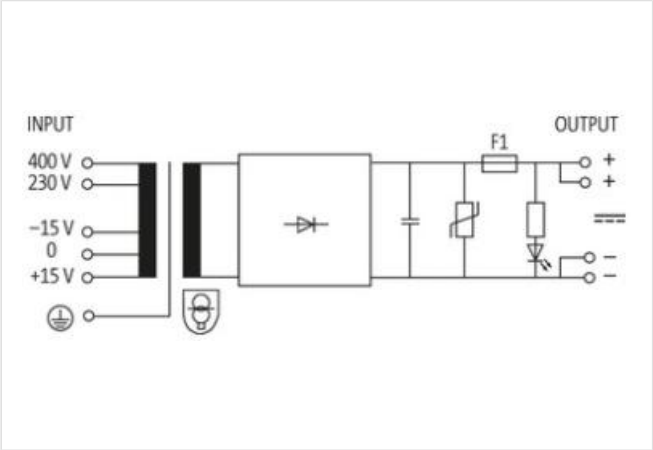

실제 제품은 이미지와 다를 수 있습니다.



제품자료	
ECLASS-6.0	27049002
ECLASS-7.0	27049002
ECLASS-8.0	27049002
ECLASS-9.0	27040701
ETIM-5.0	EC002540
GTIN	4048879079853
세번부호	85044095
포장단위	1

Electrical data

Security levelSELV

Electrical data | Supply

Power frequency50 ... 60 Hz

Electrical data | Input

Fuse protection 1 primary side external0,5 A @230 V AC

Fuse protection 2 primary side external0,3 A @400 V AC

Characteristic back-up fuseInertia

Input voltage 1 AC230 V

Input voltage 1 AC min.195,5 V

Input voltage 1 AC max.264,5 V

Input voltage 2 AC400 V

Input voltage 2 AC min.340 V

Input voltage 2 AC max.460 V

Input current at input voltage 1 AC0,37 A

Input current at input voltage 2 AC0,21 A

Electrical data | Output

Fuse protection secondary side external2 A

Output suppressionLED, Screening capacitor, VDR

Output voltage DC24 V

Output voltage adjustableno

Output current max.2 A

Characteristic secondary fuseInertia

Ripple max.5 %

Diagnostics

Status indication LEDgreen

Mechanical data | Mounting data

Mounting methodgeschnappt

Suitable for mounting typeTragschiene TH35-15, Schlüssellochtaufhängung, (EN 60715)

Mounting dimension a96 mm

Mounting dimension b60 mm

Mounting dimension c5,5 mm

Height108 mm

Width87 mm

Depth142 mm

Environmental characteristics | Climatic

Operating temperature min.-20 °C

Operating temperature max.60 °C

Conformity

Product standardEN 61558-2-6, EN 62041 category I

EMCEN 55011 B, EN 61000-3-2

Connection type 2

Connection type 1Input

Connection type 2Output

ConnectionScrew terminals SK

Family construction formterminal

Genderfemale

No. of poles5

PIN 1+ 15 V

PIN 3- 15 V

PIN 4230 V

PIN 5	400 V
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
No. of poles	5
PIN 1	PE
PIN 2	-
PIN 3	-
PIN 4	+
PIN 5	+