



GLS DC/DC-CONVERTER, LINEAR REGULATED

IN: 24VDC OUT: 5V/1,2ADC

INPUT: 24 V DC  
OUTPUT regulated: 5 V DC  
Output rating: 6 W  
Current: 1.2 A  
Condensation not permitted

제품 링크

일러스트

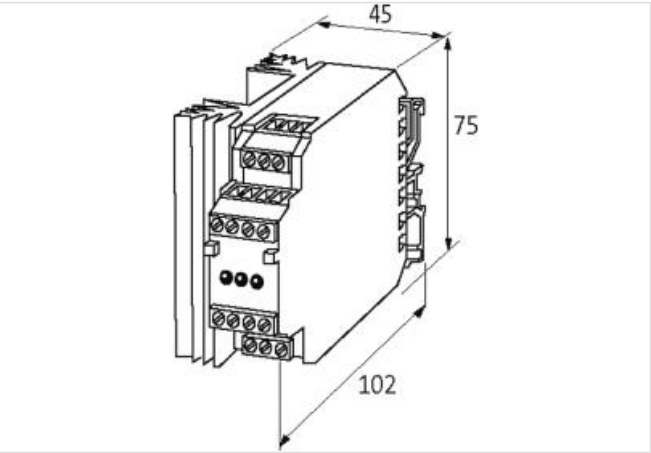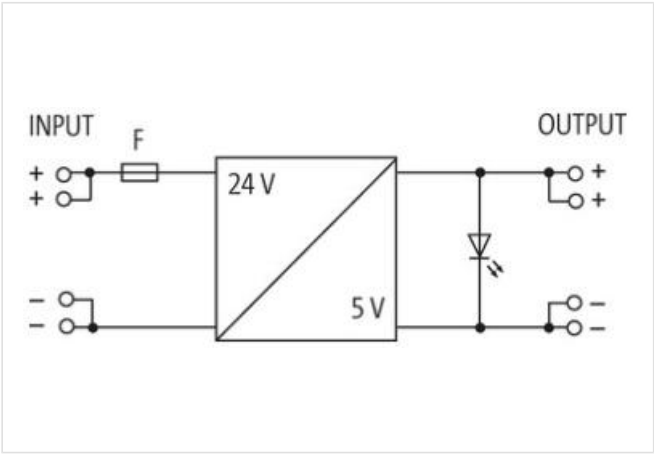

실제 제품은 이미지와 다를 수 있습니다.



| 제품자료       |          |
|------------|----------|
| ECLASS-6.0 | 27210901 |
| ECLASS-6.1 | 27210901 |
| ECLASS-7.0 | 27210901 |
| ECLASS-8.0 | 27210901 |
| ECLASS-9.0 | 27210901 |

|             |               |
|-------------|---------------|
| ECLASS-10.1 | 27210901      |
| ECLASS-11.1 | 27210901      |
| ECLASS-12.0 | 27210901      |
| ETIM-5.0    | EC002540      |
| GTIN        | 4048879079679 |
| 세번부호        | 85044095      |
| 포장단위        | 1             |

Electrical data

|                |      |
|----------------|------|
| Security level | SELV |
|----------------|------|

Electrical data | Input

|                                       |         |
|---------------------------------------|---------|
| Fuse protection primary side internal | 2 A     |
| Characteristic back-up fuse           | Inertia |
| Input voltage DC                      | 24 V    |
| Input voltage DC min.                 | 20,4 V  |
| Input voltage DC max.                 | 26,4 V  |
| Current input AC                      | 1,2 A   |

Electrical data | Output

|                           |        |
|---------------------------|--------|
| Output voltage DC         | 5 V    |
| Output voltage DC min.    | 4,75 V |
| Output voltage DC max.    | 5,25 V |
| Output voltage adjustable | no     |
| Output current max.       | 1,2 A  |
| Ripple max.               | 0,2 %  |

Device protection | Electrical

|                         |     |
|-------------------------|-----|
| Short-circuit protected | yes |
|-------------------------|-----|

Mechanical data | Mounting data

|                            |                                |
|----------------------------|--------------------------------|
| Mounting method            | geschnappt                     |
| Suitable for mounting type | Mounting rail TH35, (EN 60715) |

Environmental characteristics | Climatic

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -20 °C |
| Operating temperature max. | 60 °C  |

Connection type 1

|                          |                    |
|--------------------------|--------------------|
| Connection type 1        | Output             |
| Connection               | Screw terminals SK |
| Family construction form | terminal           |
| Gender                   | female             |
| No. of poles             | 4                  |
| PIN 1                    | +                  |
| PIN 2                    | +                  |
| PIN 3                    | -                  |
| PIN 4                    | -                  |