


MPL POWER SUPPLY 3-PHASE, SMOOTHED

IN: 208-520VAC+/- 5% OUT: 24V/15ADC

Current: 15 A
Output rating: 360 W
This power supply units meet the (EN 61000-3-2) standard for harmonic current.
Any mounting position on vertical wall, condensation not permissible

제품 링크

일러스트

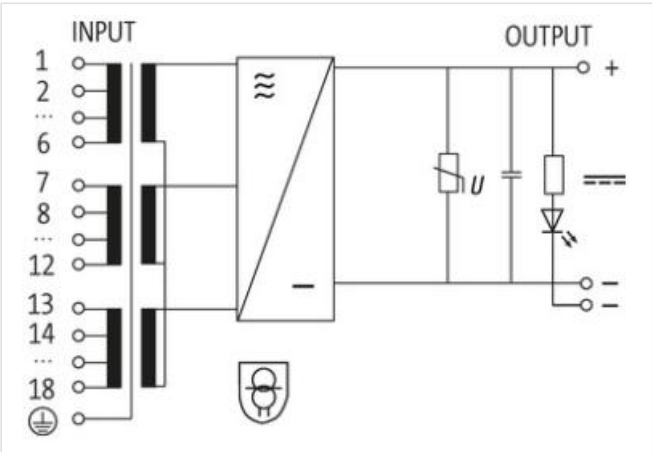

실제 제품은 이미지와 다를 수 있습니다.

제품자료	
ECLASS-6.0	27049002
ECLASS-7.0	27049002
ECLASS-8.0	27049002
ECLASS-9.0	27040701
ETIM-5.0	EC002540
GTIN	4048879079112
세번부호	85044095
포장단위	1

Electrical data	
Security level	SELV

Electrical data | Supply

Power frequency50 ... 60 Hz

Electrical data | Input

Input voltage AC min.208 V

Input voltage AC max.520 V

Phase number input3

Efficiency75 %

Electrical data | Output

Fuse protection secondary side external15 A

Output suppressionLED, Screening capacitor, VDR

Output voltage DC24 V

Output voltage adjustableno

Output current max.15 A

Characteristic secondary fuseInertia

Ripple max.2 %

Mechanical data | Mounting data

Suitable for mounting typeSchlüssellochauhängung

Mounting dimension a195 mm

Mounting dimension b59 mm

Mounting dimension c6,5 mm

Height220 mm

Width81 mm

Depth208 mm

Environmental characteristics | Climatic

Operating temperature min.-20 °C

Operating temperature max.55 °C

Conformity

Product standardEN 61558-2-6, EN 62041 category I

EMCEN 55011 B, EN 61000-3-2