



MTS 1-PHASE CONTROL AND ISOLATION TRANSFORMER

P: 40VA IN: 230/400VAC +/- 15VAC OUT: 230VAC

Single-phase - Control and Isolation Transformers  
40 VA  
Isolation class T 40/B  
Other voltages on request.

제품 링크

일러스트

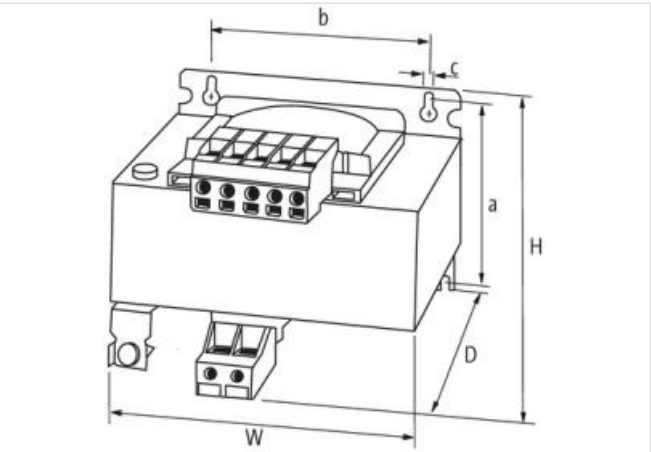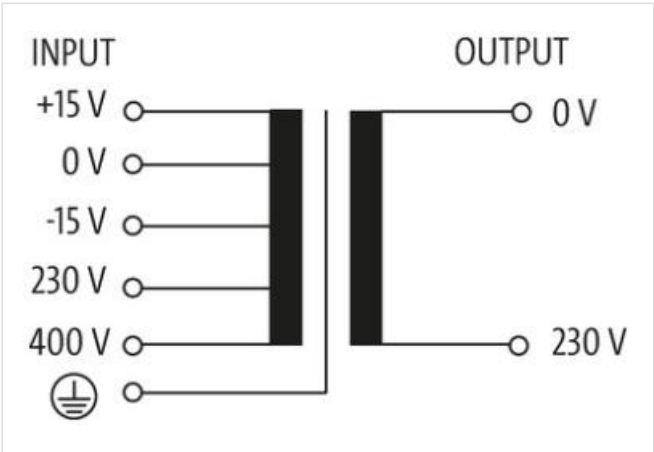

실제 제품은 이미지와 다를 수 있습니다.



| 제품자료        |          |
|-------------|----------|
| ECLASS-6.0  | 27031302 |
| ECLASS-6.1  | 27031302 |
| ECLASS-7.0  | 27031302 |
| ECLASS-8.0  | 27031302 |
| ECLASS-9.0  | 27031302 |
| ECLASS-10.1 | 27031302 |

|                                          |                                                    |
|------------------------------------------|----------------------------------------------------|
| ECLASS-11.1                              | 27031302                                           |
| ECLASS-12.0                              | 27031302                                           |
| ETIM-5.0                                 | EC002486                                           |
| GTIN                                     | 4048879078405                                      |
| 세번부호                                     | 85043180                                           |
| 포장단위                                     | 1                                                  |
| Electrical data   Supply                 |                                                    |
| Power frequency                          | 50 ... 60 Hz                                       |
| Electrical data   Input                  |                                                    |
| Input voltage 1 AC                       | 230 V                                              |
| Input voltage 1 AC min.                  | 195,5 V                                            |
| Input voltage 1 AC max.                  | 264,5 V                                            |
| Input voltage 2 AC                       | 400 V                                              |
| Input voltage 2 AC min.                  | 340 V                                              |
| Input voltage 2 AC max.                  | 460 V                                              |
| Input current at input voltage 1 AC      | 0,24 A                                             |
| Input current at input voltage 2 AC      | 0,138 A                                            |
| Inrush current at input voltage 1        | 1,64 A                                             |
| Inrush current at input voltage 2        | 0,94 A                                             |
| Short-circuit current at input voltage 1 | 1,88 A                                             |
| Short-circuit current at input voltage 2 | 1,08 A                                             |
| Electrical data   Output                 |                                                    |
| Output voltage AC                        | 230 V                                              |
| Output voltage adjustable                | no                                                 |
| Power rating AC max.                     | 40 VA                                              |
| Device protection   Electrical           |                                                    |
| Insulation test voltage input - output   | 4 kV                                               |
| Mechanical data   Mounting data          |                                                    |
| Mounting method                          | geschnappt                                         |
| Suitable for mounting type               | Mounting rail TH35, Long-hole mounting, (EN 60715) |
| Mounting dimension a                     | 56 mm                                              |
| Mounting dimension b                     | 56 mm                                              |
| Mounting dimension c                     | 4,8 mm                                             |
| Height                                   | 78 mm                                              |
| Width                                    | 78 mm                                              |
| Depth                                    | 93 mm                                              |
| Diameter bore                            | 4,8 mm                                             |
| Length bore                              | 8,4 mm                                             |
| Environmental characteristics   Climatic |                                                    |
| Operating temperature min.               | -20 °C                                             |
| Operating temperature max.               | 40 °C                                              |
| Storage temperature min.                 | -40 °C                                             |
| Storage temperature max.                 | 80 °C                                              |
| Conformity                               |                                                    |
| Product standard                         | EN 61558-1, EN 61558-2-4, EN 62041 category 0      |
| Connection type 3                        |                                                    |
| Connection type 1                        | Input                                              |
| Connection type 2                        | Output                                             |
| Connection                               | Screw terminals SK                                 |
| Family construction form                 | terminal                                           |
| Gender                                   | female                                             |

|                          |                    |
|--------------------------|--------------------|
| No. of poles             | 5                  |
| PIN 1                    | + 15 V             |
| PIN 3                    | - 15 V             |
| PIN 4                    | 230 V              |
| PIN 5                    | 400 V              |
| Connection               | Screw terminals SK |
| Family construction form | terminal           |
| Gender                   | female             |
| No. of poles             | 2                  |
| PIN 2                    | 230 V              |
| Connection               | Screw terminals SK |
| Family construction form | terminal           |
| Gender                   | female             |
| Color contact carrier    | metallic           |
| No. of poles             | 1                  |
| PIN 1                    | PE                 |