



EMC SUPPRESSOR FOR MOTOR

RC 3 R-575/4, M16x1,5/ AWG 20/VDR"

3× 575 V AC
VDR
M16×1.5 mm
Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

제품 링크

일러스트

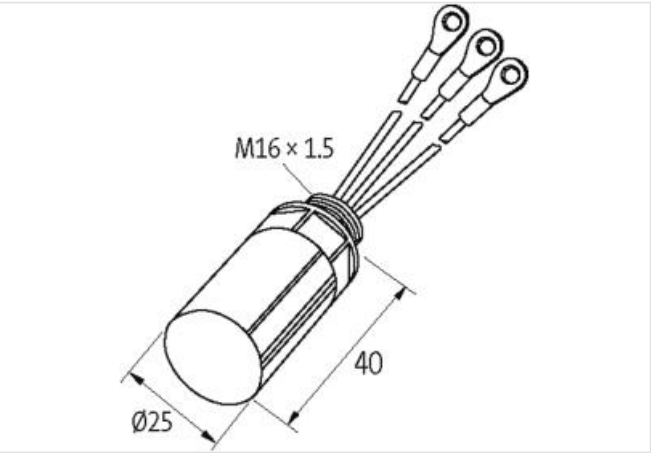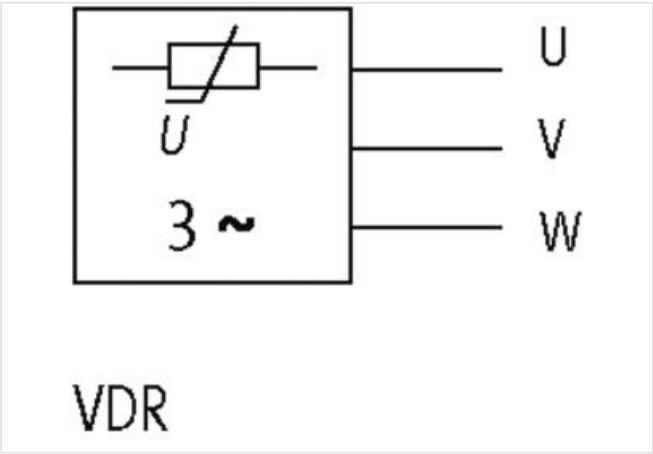

실제 제품은 이미지와 다를 수 있습니다.



제품자료	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013

ECLASS-10.1	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000197
GTIN	4048879015035
세번부호	85363010
포장단위	10

Electrical data | Input

Input voltage AC	575 V
------------------	-------

Installation

Connection cross section max.	0,5 mm²
-------------------------------	---------

Installation | Connection

Connection information	Single strands
Length single strands	100 mm
Ring terminals	M4isolated

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Combustibility class housing (UL94)	V-0
Material housing	Plastic
Material potting compound	2-component epoxy

Mechanical data | Mounting data

Mounting method	inserted
Suitable for mounting type	Motorklemmkasten
Height	25 mm
Width	25 mm
Depth	40 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C