

AMMS 10-1 OPTO-COUPLER MODULE

IN: 35 VDC - OUT: 44 VDC / 0.5 A



Transistor 0.5 A
24 V DC

제품 링크

일러스트



실제 제품은 이미지와 다를 수 있습니다.

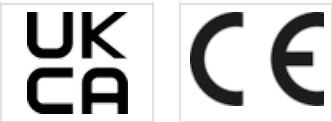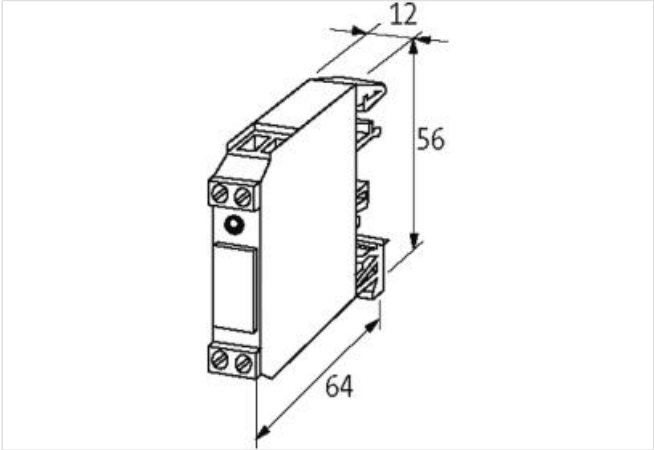

제품자료

ECLASS-6.0	27261590
ECLASS-7.0	27261590
ECLASS-8.0	27261590
ECLASS-9.0	27261590
ETIM-5.0	EC001504
GTIN	4048879411363
세번부호	85414900
포장단위	1

Electrical data | Input

Input voltage OFF DC min.	0 V
Input voltage OFF DC max.	5 V
Input voltage DC min.	10 V
Input voltage DC max.	35 V
Input current	12 mA

Electrical data | Output

Switch off delay max.	20 ms
Quiescent current OFF max.	0,3 mA
Switching frequency inductive max.	20 Hz
Switching frequency ohmic max.	7000 Hz
Voltage switching DC min.	4,5 V
Switching voltage DC max.	44 V
Switching current min.	1 mA

Switching current max.	0,5 A
Voltage drop DC max.	1,2 V
Diagnostics	
Status indication LED	red
Device protection Electrical	
Rated insulation voltage	3750 V
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Color housing	black
Material housing	Plastic
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, G32, (EN 60715)
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C